

# Impact Bit Socket

KT No. & D1

**6015M**

**3/4"**

- Hexagon head
- DIN 3121




| KT NO.  | mm  | L mm | Max. torq N·m |     |        |
|---------|-----|------|---------------|-----|--------|
| 601514M | H14 | 87   | 684           | 310 | 2 / 48 |
| 601517M | H17 | 87   | 1136          | 342 | 2 / 48 |
| 601519M | H19 | 87   | 1577          | 365 | 2 / 48 |
| 601521M | H21 | 87   | 2134          | 508 | 1 / 24 |
| 601522M | H22 | 87   | 2436          | 524 | 1 / 24 |
| 601524M | H24 | 87   | 3190          | 546 | 1 / 24 |
| 601527M | H27 | 87   | 4535          | 597 | 1 / 24 |

**609616MxxH**

**609622MxxH 3/4"**

- DIN 3121

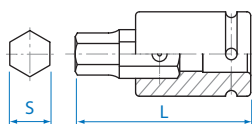

609616MxxH



609622MxxH


| KT NO.     | S mm | L mm | Max. torq N·m |      |            |
|------------|------|------|---------------|------|------------|
| 609616M10H | H10  | 16   | 77            | 264  | 416 4 / 40 |
| 609616M12H | H12  | 16   | 77            | 480  | 422 4 / 40 |
| 609616M14H | H14  | 16   | 77            | 684  | 430 4 / 40 |
| 609616M17H | H17  | 16   | 77            | 880  | 443 4 / 40 |
| 609616M19H | H19  | 16   | 77            | 880  | 450 4 / 40 |
| 609616M22H | H22  | 16   | 77            | 880  | 473 4 / 40 |
| 609622M19H | H19  | 22   | 93            | 1577 | 670 1 / 24 |
| 609622M22H | H22  | 22   | 93            | 2436 | 692 1 / 24 |
| 609622M24H | H24  | 22   | 93            | 2436 | 706 1 / 24 |
| 609622M27H | H27  | 22   | 93            | 2436 | 730 1 / 24 |
| 609622M30H | H30  | 22   | 93            | 2436 | 744 1 / 24 |
| 609622M32H | H32  | 22   | 93            | 2436 | 783 1 / 24 |

**1740**

**3/4"**

**609616M 3/4"**

- Hex bit & bit holder
- DIN 3121

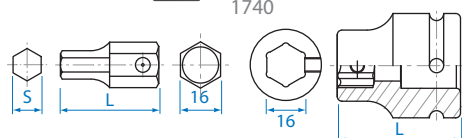


| KT NO.  | S mm | L mm | Max. torq N·m |     |          |
|---------|------|------|---------------|-----|----------|
| 174010H | H10  | 40   | 264           | 46  | 20 / 400 |
| 174012H | H12  | 40   | 480           | 55  | 20 / 400 |
| 174014H | H14  | 40   | 684           | 61  | 20 / 200 |
| 174017H | H17  | 40   | 880           | 72  | 20 / 200 |
| 174019H | H19  | 40   | 880           | 83  | 20 / 200 |
| 174022H | H22  | 40   | 880           | 102 | 12 / 120 |
| 609616M | 16   | 52   | -             | 370 | 6 / 48   |

**1954**

**3/4"**

**609622M 3/4"**

- Hex bit & bit holder
- DIN 3121

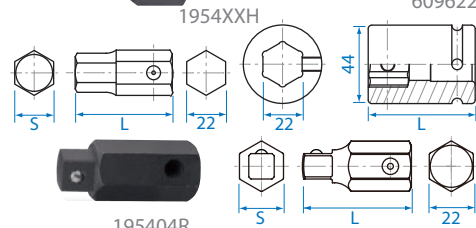

| KT NO.  | S mm  | L mm | Max. torq N·m |     |          |
|---------|-------|------|---------------|-----|----------|
| 195419H | H19   | 54.5 | 1577          | 159 | 12 / 120 |
| 195422H | H22   | 54.5 | 2436          | 176 | 12 / 120 |
| 195424H | H24   | 54.5 | 2436          | 191 | 10 / 100 |
| 195427H | H27   | 54.5 | 2436          | 217 | 10 / 100 |
| 195430H | H30   | 54.5 | 2436          | 248 | 6 / 60   |
| 195432H | H32   | 54.5 | 2436          | 276 | 6 / 60   |
| 609622M | 22    | 60.0 | -             | 530 | 6 / 48   |
| 195404R | 1/2"M | 54.5 | -             | 133 | 12 / 120 |


## Impact Accessory

 **6797**

**6797P**

**3/4"**

- Universal joint
- DIN 3121



6797



6797P


| KT NO. | Overall length<br>inch | mm  | D mm |     |        |
|--------|------------------------|-----|------|-----|--------|
| 6797   | 4-1/2                  | 114 | 44   | 738 | 2 / 20 |
| 6797P  | 4-1/2                  | 114 | 44   | 738 | 2 / 20 |

**6798**

 **6798P**

**3/4"**

- Universal joint
- DIN 3121



6798



6798P

| KT NO. | Overall length<br>inch | mm  | D (mm) | D1 (mm) |     |        |
|--------|------------------------|-----|--------|---------|-----|--------|
| 6798   | 4-1/4                  | 108 | 44     | 44      | 749 | 2 / 20 |
| 6798P  | 4-1/4                  | 108 | 44     | 44      | 749 | 2 / 20 |