 


Mini Combination Pliers

6114

- Mini type
- DIN ISO 5746




KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6114-05	5	122	3.0	2.0			87	8 / 160

Combination Pliers

6111

 - Polished head
- DIN ISO 5746




KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6111-06	6-1/2	164	4.0	2.8	1.8	1.6	220	8 / 96
6111-07	7-1/2	180	4.0	3.0	2.0	1.6	294	8 / 48
6111-08	8-1/4	205	4.0	3.0	2.0	1.6	396	8 / 48

Hi-leverage Combination Pliers

6112

 - Hi-leverage type
- Polished head



KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6112-09	9	232	4.0	3.0	2.2	2.0	395	6 / 60

Plastic Cutting Pliers


 


In order to get a normal product life of pliers, do not cut steel wire.

CAUTION

6921

- European type
- Polished head

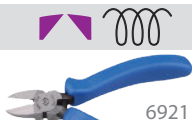


KT NO.	inch	L mm	g	box / case
6921-05	5	122	106	6 / 120
6921-06	6	155	171	6 / 72
6921-07	7	170	268	6 / 60
6921-05C	5	122	91	6 / 120
6921-06C	6	155	200	8 / 96
6921-07C	7	178	220	6 / 60

Diagonal Cutting Pliers

6214


 
- Mini type



KT NO.	inch	L mm	$\varnothing$ Max. mm	g	box / case
6214-45	4-1/2	115	0.6	83	8 / 160
6214-05	5	125	1.25	94	8 / 160

6211

  - European type
- DIN 5749




KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6211-06	6-1/2	160	4.0	2.8	2.0	1.6	194	8 / 96

Heavy Duty Diagonal Cutting Pliers


6231

 - Heavy duty type
- DIN ISO 5749



KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6231-07	7-1/2	180	4.0	3.0	2.2	2.0	243	8 / 80

 
6232



KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm				g	box / case
6232-08	8	196	5.0	3.5	2.2	2.0	285	8 / 80

6213

 - Japanese type



KT NO.	inch	L mm	Cutting capacities $\varnothing$ mm	Wire stripper mm	g	box / case
6213-06	6-1/2	168	1.25	1.4 / 1.6	175	8 / 96