

Impact Accessory

KT No. & D1



6260

- Extension bar
- DIN 3121



6260



6260P

KT NO.	Overall length inch	mm		
6260-04	4	100	566	2 / 20
6260-07	7	175	864	2 / 20
6260-10	10	250	1145	1 / 16
6260-13	13	330	1450	1 / 10
6260-04P	4	100	566	2 / 20
6260-07P	7	175	864	2 / 20
6260-10P	10	250	1145	1 / 16
6260-13P	13	330	1450	1 / 10


6864

6864P

6868

6868P 3/4"

- Adapter
- Convert to 1/2" drive
- 6864 → Max. torque : 512 N·m
- DIN 3121

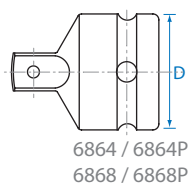

6864 / 6864P
6868 / 6868P



6864 & 6868




6864P & 6868P

KT NO.	Spec.	D (mm)		
6864	3/4"F x 1/2"M	44	311	6 / 48
6868	3/4"F x 1"M	44	445	6 / 48
6864P	3/4"F x 1/2"M	44	311	6 / 48
6868P	3/4"F x 1"M	44	445	6 / 48

6874

6874P 3/4"

- Adapter
- Convert to 1/2" drive
- 6874 → Max. torque : 512 N·m
- DIN 3121

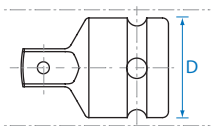

6874 / 6874P



6874



6874P

KT NO.	Spec.	D (mm)		
6874	3/4"F x 1/2"M	38	233	6 / 48
6874P	3/4"F x 1/2"M	38	233	6 / 48

90403

90404

90405 3/4"

- Locking ring
- High tensile rubber material

90603


90604

90607 3/4"

- Locking pin
- Chrome vanadium steel
- DIN 3129



90603
90604
90607

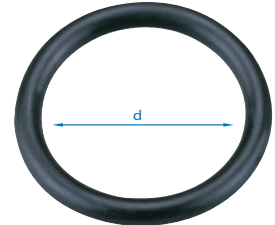

90403
90404
90405

KT NO. Type ϕ d / ℓ Applied to socket sizes

90403	ring	3.5	33	6015M (14~19mm) 6435S (3/4"~1") 6510M (17~30mm) 6535S (11/16"~1-3/16") 6515M (17~30mm) 6935S (3/4"~1") 6874
90607	pin	3.0	30	
90404	ring	5.5	37	6535M (17~46mm) 6535S (1-1/4"~1-13/16") 6435M (19~46mm) 6435S (1-1/16"~1-13/16") 6935M (19~32mm) 6935S (1-1/16"~1-1/4") 6015M (21~27mm) 6260.6797.6798.6864 6530M (17~46mm) 6868 6835M (17~32mm) 609616M.609622M
90603	pin	4.0	35	
90405	ring	5.5	44	6535M (48~65mm) 6535S (1-7/8"~2-3/8") 6435M (48~50mm) 6435S (1-7/8"~2")
90604	pin	4.0	45	

Impact Bit Socket Set

6411MP

3/4"

Metal case size (mm) :
270 x 100 x 49 (0.048 cuft)



**11
PC.**

Contents

2.77 1 / 8

	6096M	16, 22
	1740	H10, H12, H14, H17
	1954	H19, H22, H24, H27, H32