

Bit Socket

6023

3/4"

- For torx internal screw
- DIN 3120
- E.g. on commercial vehicles and agricultural machinery
- Screw of the steering tie lever on commercial vehicles MAN
- 602380 : for M series
- 6023A0 : for F series



KT NO.	Size	L mm		
602360	T60	80	246	2/48
602370	T70	80	253	2/48
602380	T80	80	326	2/48
602390	T90	80	332	2/48
6023A0	T100	80	339	2/48

6025

3/4"

- HEXAGON head
- DIN 7422



KT NO.	mm	L mm		
602514	H14	80	257	2 / 48
602517	H17	80	268	2 / 48
602519	H19	80	278	2 / 48
602522	H22	80	361	2 / 48

Ratchet

6724

3/4"

- Reversible ratchet
- 8° gear action degree (45 teeth)
- DIN 3122



KT NO.	Overall length inch mm		
6724-20F	20 500	2223	1 / 6
6724DK	renewal kits	-	-

6778

3/4"

- Quick release reversible ratchet
- 15° gear action degree (24 teeth)
- DIN 3122



KT NO.	Overall length inch mm		
6778-20FS	20 500	2612	1 / 6
6778DK	renewal kits	-	-

Ratchet & Accessory

6779

3/4"

- Reversible ratchet
- 15° gear action degree (24 teeth)
- DIN 3122



KT NO.	Overall length inch mm		
6779-20F	20 500	2449	1 / 6
6779DK	renewal kits	-	-

6251

KT No. & D1 3/4"

- Extension bar
- DIN 3123



KT NO.	Overall length inch mm		
6251-04	4 100	418	4 / 40
6251-08	8 200	734	2 / 20
6251-16	16 400	1375	1 / 10

6452

3/4"

- Flexible handle
- Action degree -180°
- DIN 3122


 


KT NO.	Overall length inch mm		
6452-18F	18 450	1768	1 / 10
6452-30F	30 750	2581	1 / 8
6452DK	renewal kits	-	-

6482

3/4"

- 180° swivel ratchet head
- 3 position ratchet control : forward / reverse / lock
- Telescopic handle : 620 mm-970 mm
- 15° gear action (24 teeth)
- DIN 3122

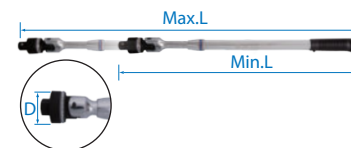

KT NO.	D mm	Min.L inch mm	Max.L inch mm		
6482-24G	46	24 620	36 970	3	1 / 6
6482DK	renewal kits	-	-	-	-