

Impact Accessory

KT No. & D1



6260

- Extension bar
- DIN 3121



6260P

3/4"

90403

- Locking ring
- High tensile rubber material

90404

90405 3/4"

90603


- Locking pin
- Chrome vanadium steel
- DIN 3129

90604

90607 3/4"



90603
90604
90607

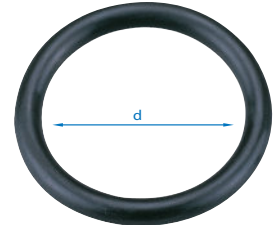

90403
90404
90405

KT NO.

Overall length
inch mm



KT NO.	Overall length inch mm	Weight g	Box
6260-04	4 100	566	2 / 20
6260-07	7 175	864	2 / 20
6260-10	10 250	1145	1 / 16
6260-13	13 330	1450	1 / 10
6260-04P	4 100	566	2 / 20
6260-07P	7 175	864	2 / 20
6260-10P	10 250	1145	1 / 16
6260-13P	13 330	1450	1 / 10

6864

6864P

6868

6868P 3/4"

- Adapter
- Convert to 1/2" drive
- 6864 → Max. torque : 512 N·m
- DIN 3121



KT NO.

Spec.

D
(mm)



KT NO.	Spec.	D (mm)	Weight g	Box
6864	3/4"F x 1/2"M	44	311	6 / 48
6868	3/4"F x 1"M	44	445	6 / 48
6864P	3/4"F x 1/2"M	44	311	6 / 48
6868P	3/4"F x 1"M	44	445	6 / 48

6874

6874P

3/4"

- Adapter
- Convert to 1/2" drive
- 6874 → Max. torque : 512 N·m
- DIN 3121



KT NO.

Spec.

D
(mm)



KT NO.	Spec.	D (mm)	Weight g	Box
6874	3/4"F x 1/2"M	38	233	6 / 48
6874P	3/4"F x 1/2"M	38	233	6 / 48

Impact Bit Socket Set

6411MP

3/4"

Metal case size (mm) :
270 x 100 x 49 (0.048 cuft)



11
PC.

Contents



2.77



1 / 8

	6096M	16, 22
	1740	H10, H12, H14, H17
	1954	H19, H22, H24, H27, H32