

Coax. Cable Stripper


6756-05

- 2-Blades model
- Material : ABS



Stripper dimension "d"	6.4 mm	
Stripper distance 2-Blades model	RG-174/58/59/62/6 3C/4C/5C (Ø 2.6 ~ Ø 8.0)	


KT NO.	Overall length inch	mm		
6756-05	5	127	68	20 / 120

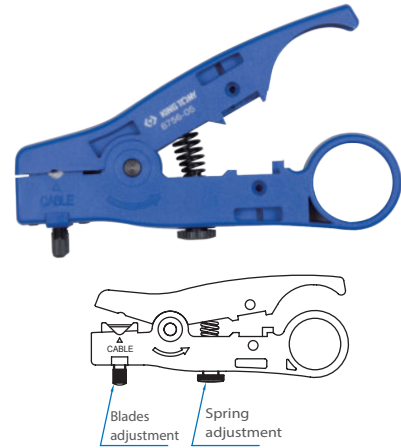

Fiber Optic Stripper

67B1-06

- Three in one model performs all common fiber stripping functions
- Safety locking system for easy and steady stripping
- Ergonomic handle for comfort grip

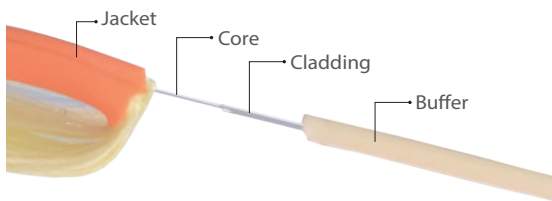

Safety locking system



- To strip the 2.0-3.0 mm fiber jacketing



- 600-900 micron buffer layer stripping



- Strips the 250 micron cable down to the glass fiber without scratching or nicking glass fiber

KT NO.	Overall length inch	mm	Stripping range mm	μm	μm		
67B1-06	6	150	2.0-3.0	600-900	250	130	10 / 100

Multi-stripper

67B2-05

KT NO.	Overall length inch	mm		
67B2-05	4-3/4	120	69	15 / 90

Stripping capacity

- Round cables between : 8-13mm
- Wire cable : 0.5 1.0 1.5 2.5 4.0 6.0mm²
- AWG : 20 18 16 14 12 10
- Coax.cable : RG-6 / RG-59

