

Socket & Tool Set


7010MR

7510MR

1/4"+1/2"

Blow case size (mm) :
422 x 360 x 110 (0.59 cuft)


110
PC.

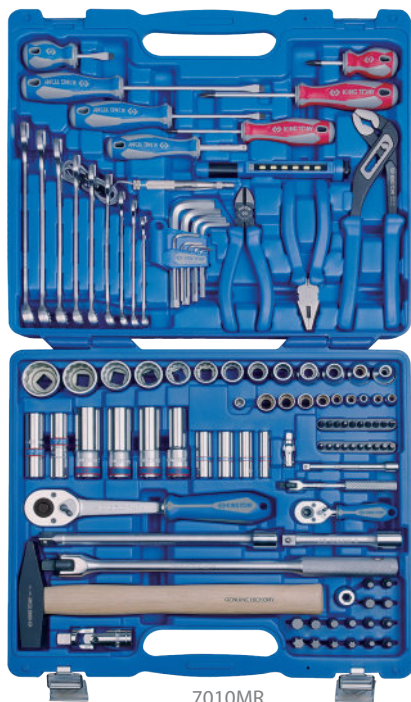

7010MR



7510MR

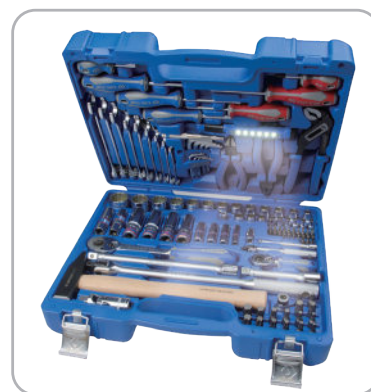

KT NO.

Contents

9.2 1/2

7010MR	 8, 10, 12, 13 2230M	 PH0, PH1, PH2, PH3 1025P	 1.5, 2, 2.5, 3, 4, 5, 6, 8, 10 1145MR
	 5, 5.5, 6, 7, 8, 10, 12, 13, 14 2330M	 H2.5, H3, H4, H5, H6 1025H	 8, 10, 12, 13, 14, 15, 17, 18, 19 1060
	 14, 17, 19, 22 4230M	 3, 4, 5, 6.5 1025S	 4771-10GR
	 8, 10, 12, 13, 14, 15, 17, 18, 19, 22, 24, 27, 30 4330MR	 T15, T20, T25, T27, T30 1025T	 276A-04G
	 463014RC  463016RC	 PZ1, PZ2 1025Z	 2178DF  6111-06  6211-06
7510MR	 8, 10, 12, 13 2235M	 H5, H6, H7, H8, H10, H12 1636H	 4452-15FR
	 5, 5.5, 6, 7, 8, 10, 12, 13, 14 2335M	 M6, M8, M10, M12 1636M	 2452-05F
	 14, 17, 19, 22 4235M	 T30, T40, T45, T50, T55, T60 1636T	 4251-05R  2221-04
	 8, 10, 12, 13, 14, 15, 17, 18, 19, 22, 24, 27, 30 4335MR	 No.1 x 80, No.2 x 100, No.2 x 38 1421	 9DC22  7821-50
	 463514RC  463516RC	 5.5 x 100, 6.5 x 150, 6.5 x 38 1422	 4791R  2792  414810M
			 2141