

Socket & Tool Set

7028MR

7528MR

7528MR01

1/4"+1/2"

Blow case size (mm) :
560 x 400 x 110 (0.87 Cuft)


128
PC.




HAND SOCKET & ACCESSORIES



7028MR

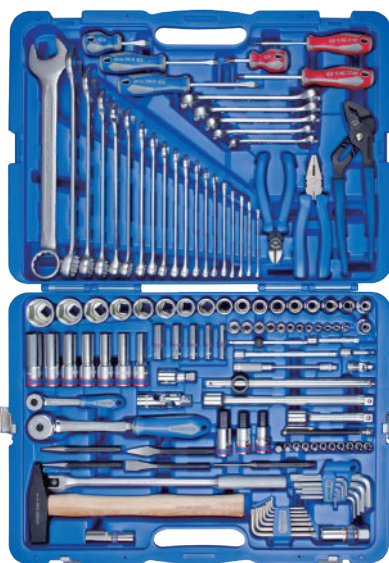

7528MR

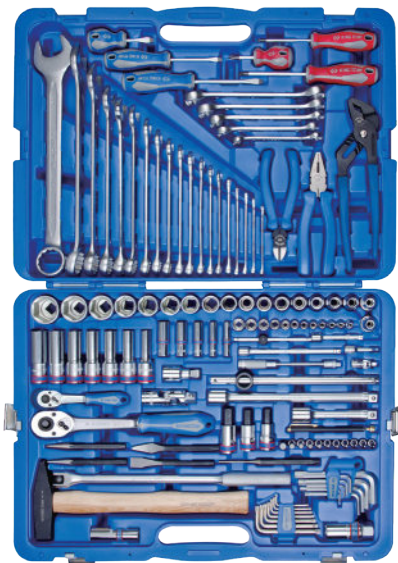

7528MR01

KT NO.	Contents		14.95	1 / 2
7028MR	4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13 2330M		6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 19, 21, 22, 24, 27, 30, 32 1060	
	7, 8, 10, 12, 13 2230M		8 x 10, 9 x 11, 12 x 13, 14 x 17, 17 x 19 1930	
	10, 12, 13, 14, 15, 17, 19 4230M	2755-55G	T10, T15, T20, T25, T27, T30, T40 1143	
	8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 24, 27, 30, 32 4330MR	4755-10G	H1.5, H2, H2.5, H3, H4, H5, H6, H8, H10 1145	
	463016RC 463021RC		PH1 x 80, PH2 x 38, PH2 x 100 1421	
7528MR	4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13 2335M		5 x 75, 6.5 x 38, 6.5 x 100 1422	
	7, 8, 10, 12, 13 2235M	2755-55G	T10, T15, T20, T25, T27 2033	
	10, 12, 13, 14, 15, 17, 19 4235M	4755-10G	H4, H5, H6, H7, H8, H10 2035	2311-06
	8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 21, 22, 24, 27, 30, 32 4335MR		H12, H14, H17 4025	2293-02 2293-06
	463516RC 463521RC		7821-50	2221-03 2221-06
7528MR01		2771-55G	6111-07	4251-05R 4251-10R
			6211-06	76215-05
		4771-10GR	6511-10C	76404-06
			4452-15FR	76505-05
			2571-45	76104-05
			4572-10	76303-05
				2128-26
				4223-02R
				2792
				4791R