


Standard Cable Entry Plates




- For standard industrial applications, to be used instead of standard cable glands, when the space on the enclosure is limited and also as an economical solution
- The cable entry plates are designed for connectorised and non-connectorised cables.
- Material:
 - Frames, Plates and Inserts: PA Glass Fibre reinforced
 - Clamping Seals: CR
 - Main Frame Seal: Polyurethane
 - Screws, Locknut: Steel / Washers (Screws): NBR
- Ingress Protection Rating: Type 12, 13 / Type 4X / IP66
- Flammability: HB According to UL94
- Operating temperature: -40 °C to +80 °C

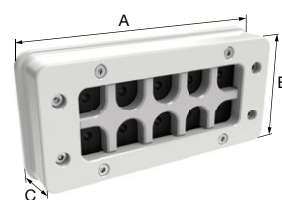


No. of Cable Entries	Seal Quantity per Frame	Frame								Light grey RAL 7035				Black RAL 9005				Pkg per Box
		Width A		Height B		Depth C		Description		Part Number		Description		Part Number				
		mm	in	mm	in	mm	in											
4 (2B+2A)	2 small (type A) 2 large (type B)	156.5	6.161	75.5	2.972	27.5	1.083	EP-BPA-SZ4-LGR-A	1SNG604001R0000	EP-BPA-SZ4-BL-A	1SNG604002R0000	1						
7 (1B+6A)	6 small (type A) 1 large (type B)	156.5	6.161	75.5	2.972	27.5	1.083	EP-BPA-SZ7-LGR-A	1SNG604003R0000	EP-BPA-SZ7-BL-A	1SNG604004R0000	1						
10 (0B+10A)	10 small (type A)	156.5	6.161	75.5	2.972	27.5	1.083	EP-BPA-SZ10-LGR-A	1SNG604005R0000	EP-BPA-SZ10-BL-A	1SNG604006R0000	1						


Seal Dimensions							Pkg	
Seal Size	Related Union Seal	Central Ø After Peeling mm	<i>in</i>	Cable Clamping Range Ø mm	<i>in</i>	Description	Part Number	per Box
A1	01-04/06	1	0.039	3.5 to 5.5	0.138-0.217	EP-BPA-SZ1-BL-A	1SNG604007R0000	500
	02-06/07	2	0.079	5.5 to 7.5	0.217-0.295			
	03-08/09	3	0.118	7.5 to 9.5	0.295-0.374			
A2	01-010/011	1	0.039	9.5 to 11.5	0.374-0.453	EP-BPA-SZ2-BL-A	1SNG604008R0000	500
	02-012/013	2	0.079	11.5 to 13.5	0.453-0.531			
	03-014/015	3	0.118	13.5 to 15.5	0.531-0.610			
B1	01-016/017	1	0.039	15.5 to 17.5	0.610-0.689	EP-BPA-SZ3-BL-A	1SNG604009R0000	300
	02-018/019	2	0.079	17.5 to 19.5	0.689-0.768			
	03-020/21	3	0.118	19.5 to 21.5	0.768-0.846			
B2	01-022/23	1	0.039	21.5 to 23.5	0.846-0.925	EP-BPA-SZ4-BL-A	1SNG604010R0000	200
	02-024/25	2	0.079	23.5 to 25.5	0.925-1.041			
	03-026/27	3	0.118	25.5 to 27.5	1.041-1.083			
	04-028/29	4	0.157	27.5 to 29.5	1.083-1.161			

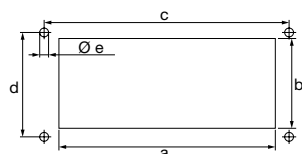


a mm	b mm	c mm	d mm	e mm
112	46	130	32	5

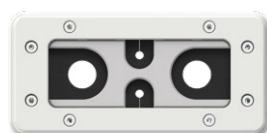

4 Ways

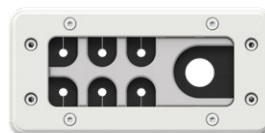

7 Ways

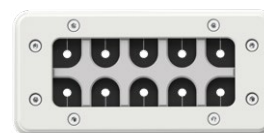

10 Ways

RoHS RoHS RoHS