


Hex nuts ~0,8d

BN 504

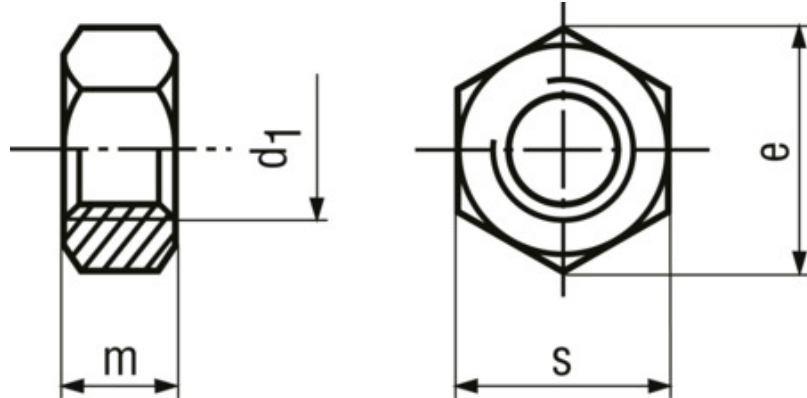

Standard

~DIN 934 (Standard withdrawn), ~ISO 4032, ~UNI 5588, ~ČSN 021401

Material

Brass

Surface

plain

M10; M12; M14; M22: wrench size according to ISO on request

Article no.	d1	e min.	s	m max.
1159402	M1	2,71	2,5	0,8
1159410	M1,2	3,28	3	1
1159429	M1,4	3,28	3	1,2
1159437	M1,6	3,41	3,2	1,3
1195069	M2	4,32	4	1,6
1159488	(M2,3)	5,2	4,5	1,8
1195093	M2,5	5,45	5	2
1195107	(M2,6)	5,45	5	2
1195115	M3	6,01	5,5	2,4
1159496	(M3,5)	6,58	6	2,8
1195131	M4	7,66	7	3,2
1195158	M5	8,79	8	4
1195166	M6	11,05	10	5
1159518	(M7)	12,12	11	5,5
1195182	M8	14,38	13	6,5
1195190	M10	18,9	17	8
1195204	M12	21,1	19	10
5505450	(M14)	24,49	22	11
1195220	M16	26,75	24	13
8036535	(M18)	29,56	27	15
1195247	M20	32,95	30	16
1159526	(M22)	35,03	32	18

Article no.	d1	e min.	s	m max.
1159534	M24	39,55	36	19