


Hex head screws fully threaded, with metric fine thread

BN 65

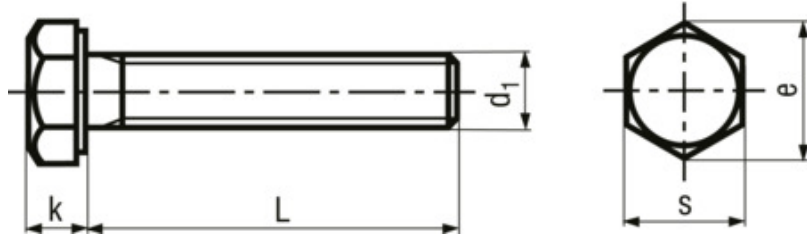

Standard	DIN 961 (Standard withdrawn), ISO 8676, ~UNI 5740
Headform	Hexagon
Drive	Hexagon
Thread	fully threaded
Material	Steel
Property class	8.8
Surface	black

M10; M12; M14; M22: wrench size according to ISO on request

Article no.	d1	L	e	k	s
1055666	M8x1	16	14,38	5,3	13
1055682	M8x1	20	14,38	5,3	13
1055704	M8x1	25	14,38	5,3	13
1055712	M8x1	30	14,38	5,3	13
3092077	M8x1	35	14,38	5,3	13
1808427	M10x1	20	18,9	6,4	17
1808443	M10x1	25	18,9	6,4	17
1808451	M10x1	30	18,9	6,4	17
1808478	M10x1	35	18,9	6,4	17
3092734	M10x1	40	18,9	6,4	17
1055828	M10x1,25	18	18,9	6,4	17
1055836	M10x1,25	20	18,9	6,4	17
1055844	M10x1,25	(22)	18,9	6,4	17
1055852	M10x1,25	25	18,9	6,4	17

Article no.	d1	L	e	k	s
1055860	M10x1,25	30	18,9	6,4	17
1055879	M10x1,25	35	18,9	6,4	17
3059338	M10x1,25	40	18,9	6,4	17
1055984	M12x1,25	20	21,1	7,5	19
1055992	M12x1,25	25	21,1	7,5	19
1056018	M12x1,25	30	21,1	7,5	19
1056026	M12x1,25	35	21,1	7,5	19
1056034	M12x1,25	40	21,1	7,5	19
1808486	M12x1,5	20	21,1	7,5	19
1808494	M12x1,5	25	21,1	7,5	19
1808508	M12x1,5	30	21,1	7,5	19
1808516	M12x1,5	35	21,1	7,5	19
1808524	M12x1,5	40	21,1	7,5	19
1056123	(M14x1,5)	25	24,49	8,8	22
1056131	(M14x1,5)	30	24,49	8,8	22
1056158	(M14x1,5)	35	24,49	8,8	22
1056166	(M14x1,5)	40	24,49	8,8	22
1056174	(M14x1,5)	45	24,49	8,8	22
1056247	M16x1,5	30	26,75	10	24
1056255	M16x1,5	35	26,75	10	24
1056263	M16x1,5	40	26,75	10	24
1056271	M16x1,5	45	26,75	10	24
1056298	M16x1,5	50	26,75	10	24
1056360	(M18x1,5)	40	30,14	11,5	27
1056379	(M18x1,5)	50	30,14	11,5	27
1056441	M20x1,5	40	33,53	12,5	30
1056468	M20x1,5	45	33,53	12,5	30
1056476	M20x1,5	50	33,53	12,5	30
1056484	M20x1,5	60	33,53	12,5	30
1056530	(M22x1,5)	50	35,72	14	32
1056549	(M22x1,5)	60	35,72	14	32
1056603	M24x2	50	39,98	15	36
1056611	M24x2	60	39,98	15	36
1056638	M24x2	70	39,98	15	36