


ecosyn®-MRX

BN 14727 - Pozi pan head self-drilling screws form Z

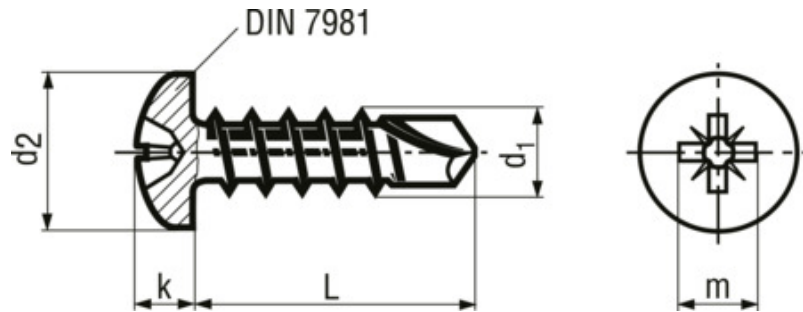

Standard ~DIN 7504 N (Standard withdrawn), ~UNI 8118

Manufacturer

ecosyn®-MRX

Additional information

A technical brochure is available on request

Headform

Pan Head

Drive

Cross recess Z (Pozidriv)

Thread

fully threaded


Brand

ecosyn®-MRX

Material

Stainless steel

Illustration assembly

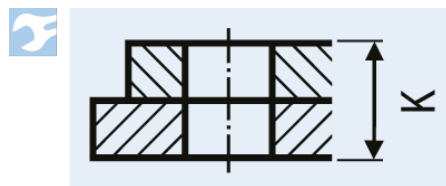

Warnings

Fasteners out of martensitic stainless steel (e.g. 1.4116 / 1.4122 / 1.4034): susceptible to stress corrosion cracking under certain environmental conditions! Further notice to residual risks can be found in the introduction section (I).

Article no.	d1	L	d2 max.	k max.	Pozidriv	m~	Clamping range (K)
1477218	ST 3,5	9,5	6,9	2,6	2	3,9	1,3-2,25
1477226	ST 3,5	13	6,9	2,6	2	3,9	1,3-2,25

Article no.	d1	L	d2 max.	k max.	Pozidriv	m~	Clamping range (K)
1477242	ST 3,5	16	6,9	2,6	2	3,9	1,3-2,25
3484314	ST 3,5	19	6,9	2,6	2	3,9	1,3-2,25
3484315	ST 3,5	22	6,9	2,6	2	3,9	1,3-2,25
3484316	ST 3,5	25	6,9	2,6	2	3,9	1,3-2,25
1477250	(ST 3,9)	13	7,5	2,8	2	4,1	1,3-2,4
1477269	(ST 3,9)	16	7,5	2,8	2	4,1	1,3-2,4
1477277	(ST 3,9)	19	7,5	2,8	2	4,1	1,3-2,4
3484317	(ST 3,9)	22	7,5	2,8	2	4,1	1,3-2,4
1478664	(ST 3,9)	25	7,5	2,8	2	4,1	1,3-2,4
3484318	(ST 3,9)	32	7,5	2,8	2	4,1	1,3-2,4
3484321	ST 4,2	13	8,2	3,05	2	4,3	1,75-3
1478672	ST 4,2	16	8,2	3,05	2	4,3	1,75-3
1478680	ST 4,2	19	8,2	3,05	2	4,3	1,75-3
1478699	ST 4,2	25	8,2	3,05	2	4,3	1,75-3
1478702	ST 4,2	32	8,2	3,05	2	4,3	1,75-3
3484322	ST 4,2	38	8,2	3,05	2	4,3	1,75-3
1478710	ST 4,8	13	9,5	3,55	2	4,7	1,75-4,4
1478729	ST 4,8	16	9,5	3,55	2	4,7	1,75-4,4
1478737	ST 4,8	19	9,5	3,55	2	4,7	1,75-4,4
1478745	ST 4,8	25	9,5	3,55	2	4,7	1,75-4,4
1478761	ST 4,8	32	9,5	3,55	2	4,7	1,75-4,4
3484324	ST 4,8	38	9,5	3,55	2	4,7	1,75-4,4
3484325	ST 4,8	45	9,5	3,55	2	4,7	1,75-4,4
1478788	ST 4,8	50	9,5	3,55	2	4,7	1,75-4,4
3484326	ST 4,8	60	9,5	3,55	2	4,7	1,75-4,4