


Starlock® HC/S

BN 30724 - Circlips for shafts without groove with cap

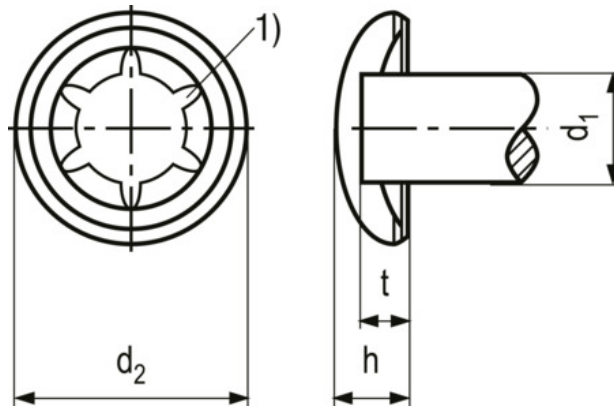

Manufacturer

Starlock®

Product description

- Cap: stainless steel

Brand

Starlock®

Brandtype

HC/S

Material

Spring steel

Surface

black-oxidized, hydroclear

d1: ≤16 ±0,05; >16 ±0,1

1) Number of lock tabs at manufacturer's option

Article no.	d1 ±0,05	d1 ±0,1	d2 ±0,2	d3 ±0,1	d3 ±0,3	h ±0,3	t +0/-0,2	Pull-off force [N]	Code
3820626	2	-	10,6	-	2	3	2,5	200	HC-6662/S
5401551	3	-	10,6	-	-	3	2,5	200	HC-6663/S
5401552	4	-	12,3	-	-	3,8	3	390	HC-6665/S
5401553	5	-	12,3	-	-	3,8	3	390	HC-6664/S
5401554	6	-	16,1	-	-	5,1	4	790	HC-6666/S
3820621	7	-	16,1	-	7	5,1	4	790	HC-6670/S
5401556	8	-	16,1	-	-	5,1	4	790	HC-6671/S
3820350	9	-	19,7	-	9	5,8	4,5	980	HC-6674/S
5401557	10	-	19,7	-	-	5,8	4,5	980	HC-6668/S
3820596	11	-	19,7	-	11	5,8	4,5	980	HC-6673/S
5401558	12	-	26	-	-	7,5	6	2450	HC-6675/S
3820084	12,7	-	26	-	12,7	7,5	6	2450	HC-6229/S
3820069	14	-	29,4	-	14	9	7	2450	HC-6881/S
3820151	15	-	29,4	-	15	9	7	2450	HC-6676/S

Article no.	d1 ±0,05	d1 ±0,1	d2 ±0,2	d3 ±0,1	d3 ±0,3	h ±0,3	t +0/-0,2	Pull-off force [N]	Code
3820355	-	16	29,4	-	16	9	7	2450	HC-6882/S
3820425	-	17	29,4	17	-	9	7	2450	HC-6677/S
3820498	-	18	38,2	18	-	11,7	8,7	3430	HC-6883/S
3820344	-	20	38,2	20	-	11,7	8,7	3430	HC-6678/S
3820423	-	22	38,2	22	-	11,7	8,7	3430	HC-6889/S
3820141	-	24	43	24	-	12,5	9,5	3780	HC-6888/S
3820383	-	25	43	25	-	12,5	9,5	3780	HC-6679/S