




SS001

**Stainless Steel Central Nut
Adjustable Wrenches**



PRODUCT DETAILS

- AISI 420 stainless steel body
- Magnetic
- High strength and hardness
- Can be Autoclave Sterilized at 121°C
- Produced according to ISO 6787

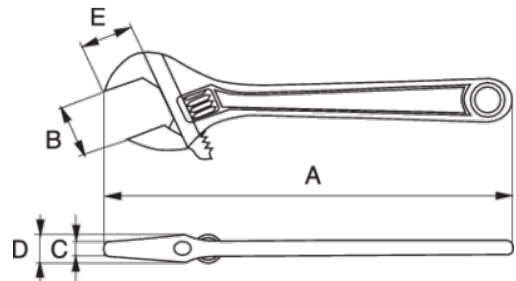

Follow the Fish!



PRODUCT ATTRIBUTES

Product	A	A	B	C	D	E	
SS001-100	100 mm	4 in	13 mm	10 mm	7 mm	12 mm	100 g
SS001-150	150 mm	6 in	18 mm	8 mm	13 mm	18 mm	120 g
SS001-200	200 mm	8 in	24 mm	9 mm	15 mm	24 mm	240 g
SS001-250	250 mm	10 in	30 mm	10 mm	16 mm	28 mm	400 g
SS001-300	300 mm	12 in	36 mm	11 mm	19 mm	33 mm	340 g
SS001-375	375 mm	15 in	46 mm	14 mm	24 mm	42 mm	1360 g
SS001-450	450 mm	18 in	55 mm	15 mm	27 mm	51 mm	1840 g
SS001-600	600 mm	24 in	60 mm	20 mm	33 mm	62 mm	3200 g

Follow the Fish!

