




SS002

Stainless Steel Metric Offset Combination Wrenches



PRODUCT DETAILS

- AISI 420 stainless steel body
- Magnetic
- Ring end angle 15° for knuckle clearance or better grip
- High strength and hardness
- Can be Autoclave Sterilized at 121°C
- Produced according to ISO 691

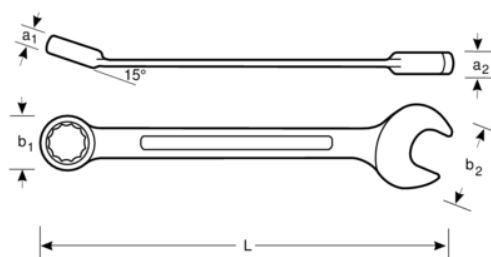

Follow the Fish!



PRODUCT ATTRIBUTES

Product		a1	a2	b1	b2	L	
SS002-7	7 in	5 mm	6 mm	17 mm	14 mm	120 m	40 g
SS002-6	6 mm	5 mm	4 mm	11 mm	13 mm	105 mm	25 g
SS002-8	8 mm	5.5 mm	4.5 mm	14 mm	17 mm	120 mm	25 g
SS002-10	10 mm	5.5 mm	4.5 mm	14 mm	17 mm	120 mm	25 g
SS002-11	11 mm	6 mm	5 mm	17 mm	21 mm	135 mm	45 g
SS002-12	12 mm	6 mm	5 mm	17 mm	21 mm	135 mm	45 g
SS002-13	13 mm	6 mm	5.5 mm	20 mm	25 mm	150 mm	60 g
SS002-14	14 mm	6 mm	5.5 mm	20 mm	25 mm	150 mm	60 g
SS002-15	15 mm	7 mm	6 mm	23 mm	28 mm	175 mm	80 g
SS002-16	16 mm	7 mm	6 mm	23 mm	28 mm	175 mm	70 g
SS002-17	17 mm	8 mm	6.5 mm	27 mm	33 mm	195 mm	115 g
SS002-19	19 mm	8 mm	6.5 mm	27 mm	33 mm	195 mm	115 g
SS002-21	21 mm	8 mm	6.5 mm	27 mm	33 mm	195 mm	110 g
SS002-22	22 mm	9 mm	7 mm	30 mm	37 mm	215 mm	160 g
SS002-24	24 mm	9 mm	7 mm	30 mm	37 mm	215 mm	160 g
SS002-27	27 mm	9 mm	7 mm	30 mm	37 mm	215 mm	160 g
SS002-32	32 mm	9 mm	7 mm	30 mm	37 mm	245 mm	160 g

Follow the Fish!

