




SS003

Stainless Steel Imperial Combination Wrenches



PRODUCT DETAILS

- AISI 420 stainless steel body
- Magnetic
- Ring end angle 15° for knuckle clearance or better grip
- High strength and hardness
- Can be Autoclave Sterilized at 121°C
- Produced according to ISO 691

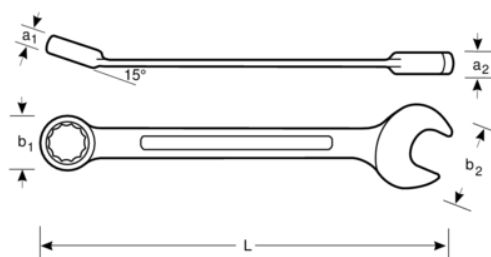

Follow the Fish!



PRODUCT ATTRIBUTES

Product		a1	a2	b1	b2	L	
SS003-8	1/4 in	5 mm	4 mm	11 mm	13 mm	105 mm	20 g
SS003-10	5/16 in	5.5 mm	4.5 mm	14 mm	17 mm	120 mm	25 g
SS003-11	11/32 in	6 mm	5 mm	17 mm	21 mm	135 mm	45 g
SS003-12	3/8 in	6 mm	5 mm	17 mm	21 mm	135 mm	45 g
SS003-14	7/16 in	6 mm	5.5 mm	20 mm	25 mm	150 mm	60 g
SS003-16	1/2 in	7 mm	6 mm	23 mm	28 mm	175 mm	80 g
SS003-18	9/16 in	7 mm	6 mm	23 mm	28 mm	175 mm	80 g
SS003-20	5/8 in	8 mm	6.5 mm	27 mm	33 mm	195 mm	115 g
SS003-22	11/16 in	8 mm	6.5 mm	27 mm	33 mm	195 mm	115 g
SS003-24	3/4 in	9 mm	7 mm	30 mm	37 mm	215 mm	160 g
SS003-25	25/32 in	9 mm	7 mm	30 mm	37 mm	215 mm	160 g
SS003-26	13/16 in	10 mm	7.5 mm	35 mm	43 mm	245 mm	160 g
SS003-28	7/8 in	10 mm	7.5 mm	35 mm	43 mm	245 mm	160 g
SS003-30	15/16 in	11 mm	8 mm	38 mm	47 mm	265 mm	160 g

