




SS242

Stainless Steel Reversible Ratchets



PRODUCT DETAILS

- AISI 420 stainless steel body
- Magnetic
- High strength and hardness
- Can be Autoclave Sterilized at 121°C
- Produced according to ISO 3315

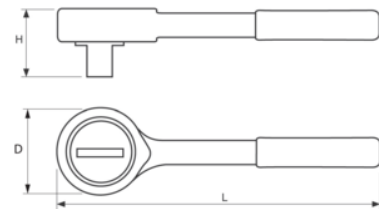

PRODUCT ATTRIBUTES

Product		H	L	 g
SS242-08-200	1/4"	30 mm	200 mm	280 g
SS242-16-245	1/2"	43 mm	245 mm	660 g
SS242-24-320	3/4"	57 mm	320 mm	1530 g

Follow the Fish!

