

Technical data sheet

Flat cable threaded connection, PG thread rectangular
version, stone grey
Item no. 2012774



Flat-cable entry, choke-nipple design with PG connecting thread to DIN 40430, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data


Item no.	2012774
Type	106 FL 29 14 40
Description 1	Flat cable threaded connection
Dimension	PG29
Colour	Stone grey
RAL number	7030
Material	Polyethylene
Material symbol	PE
Smallest sales unit (VG)	15,00 Piece
Weight	3,50 kg/100 pc.

Technical data sheet

Flat cable threaded connection, PG thread rectangular
version, stone grey
Item no. 2012774



Technical data

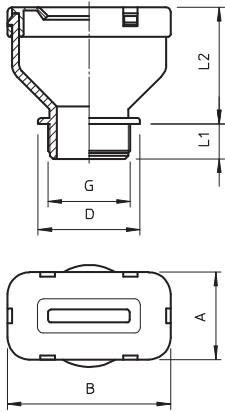

Flat cable/width	37,00 - 40,00 mm
Dimension A	30,00 mm
Dimension B	56,00 mm
Dimension D	46,00 mm
Dimension G	PG29 mm
Dimension L	59,00 mm
Dimension L1	13,00 mm
Dimension L2	46,00 mm
Type of seal	Sealing ring
Bend protection	☐
Flat cable/thickness	11,00 - 14,00 mm
Flat cable threaded connection	☒
For Ex zone	Without
Thread	Pg 29
Thread type	PG
Fibre-glass reinforced	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP31
Strain relief option	☐