

Technical data sheet

Flat cable threaded connection, PG thread rectangular
version, stone grey
Item no. 2012847



Flat-cable entry, choke-nipple design with PG connecting thread to DIN 40430, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data


Item no.	2012847
Type	106 FL 21 12 35
Description 1	Flat cable threaded connection
Dimension	PG21
Colour	Stone grey
RAL number	7030
Material	Polyethylene
Material symbol	PE
Smallest sales unit (VG)	25,00 Piece
Weight	1,97 kg/100 pc.

Technical data sheet

Flat cable threaded connection, PG thread rectangular
version, stone grey
Item no. 2012847



Technical data

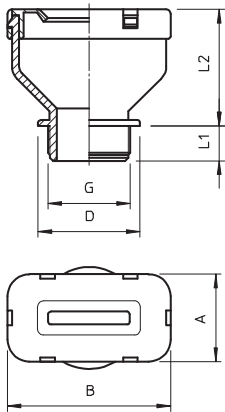

Flat cable/width	31,00 - 35,00 mm
Dimension A	30,00 mm
Dimension B	56,00 mm
Dimension D	35,00 mm
Dimension G	PG21 mm
Dimension L	52,00 mm
Dimension L1	12,00 mm
Dimension L2	40,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Flat cable/thickness	9,00 - 12,00 mm
Flat cable threaded connection	☒
For Ex zone	Without
Thread	Pg 21
Thread type	PG
Fibre-glass reinforced	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP31
Strain relief option	☐