

Technical data sheet

Flat cable threaded connection, metric thread M25,
stone grey
Item no. 2013008



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data


Item no.	2013008
Type	106 FL M25 9 22
Description 1	Flat cable threaded connection
Dimension	M25
Colour	Stone grey
RAL number	7030
Material	Polyethylene
Material symbol	PE
Smallest sales unit (VG)	25,00 Piece
Weight	2,63 kg/100 pc.

Technical data sheet

Flat cable threaded connection, metric thread M25,
stone grey
Item no. 2013008



Technical data

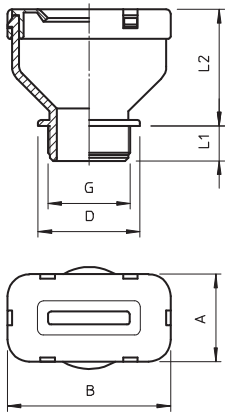

Flat cable/width	19,00 - 22,00 mm
Dimension A	30,00 mm
Dimension B	56,00 mm
Dimension D	35,00 mm
Dimension G	M25 mm
Dimension L	52,00 mm
Dimension L1	12,00 mm
Dimension L2	40,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☒
explosion-proof	☐
Flat cable/thickness	7,00 - 9,00 mm
Flat cable threaded connection	☒
For Ex zone	Without
Thread	M25
Thread type	Metric
Fibre-glass reinforced	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP31
Strain relief option	☐