

Technical data sheet

Flat cable threaded connection, metric thread M32,
stone grey
Item no. 2013016



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data


Item no.	2013016
Type	106 FL M32 8 33
Description 1	Flat cable threaded connection
Dimension	M32
Colour	Stone grey
RAL number	7030
Material	Polyethylene
Material symbol	PE
Smallest sales unit (VG)	15,00 Piece
Weight	3,45 kg/100 pc.

Technical data sheet

Flat cable threaded connection, metric thread M32,
stone grey
Item no. 2013016



Technical data

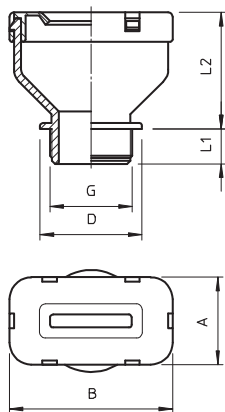

Flat cable/width	30,00 - 33,00 mm
Dimension A	30,00 mm
Dimension B	56,00 mm
Dimension D	46,00 mm
Dimension G	M32 mm
Dimension L	59,00 mm
Dimension L1	13,00 mm
Dimension L2	46,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☒
explosion-proof	☐
Flat cable/thickness	6,00 - 8,00 mm
Flat cable threaded connection	☒
For Ex zone	Without
Thread	M32
Thread type	Metric
Fibre-glass reinforced	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP31
Strain relief option	☐