

Technical data sheet

Flat cable threaded connection, metric thread M20,
stone grey
Item no. 2013002



Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP 31, with pre-mounted support sealing ring 107/F.



PE Polyethylene

Master data


Item no.	2013002
Type	106 FL M20 8 19
Description 1	Flat cable threaded connection
Dimension	M20
Colour	Stone grey
RAL number	7030
Material	Polyethylene
Material symbol	PE
Smallest sales unit (VG)	50,00 Piece
Weight	0,91 kg/100 pc.

Technical data sheet

Flat cable threaded connection, metric thread M20,
stone grey
Item no. 2013002



Technical data

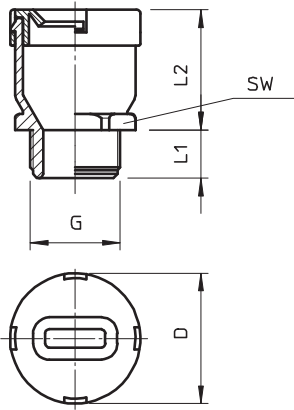

Flat cable/width	17,00 - 19,00 mm
Dimension D	32,50 mm
Dimension G	M20 mm
Dimension L	42,00 mm
Dimension L1	12,00 mm
Dimension L2	30,00 mm
WAF	27,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
explosion-proof	☐
Flat cable/thickness	6,00 - 8,00 mm
Flat cable threaded connection	☒
For Ex zone	Without
Thread	M20
Thread type	Metric
Fibre-glass reinforced	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP31
Strain relief option	☐