


Technical data sheet

Twin gland, metric thread, light grey

Item no. 2024063

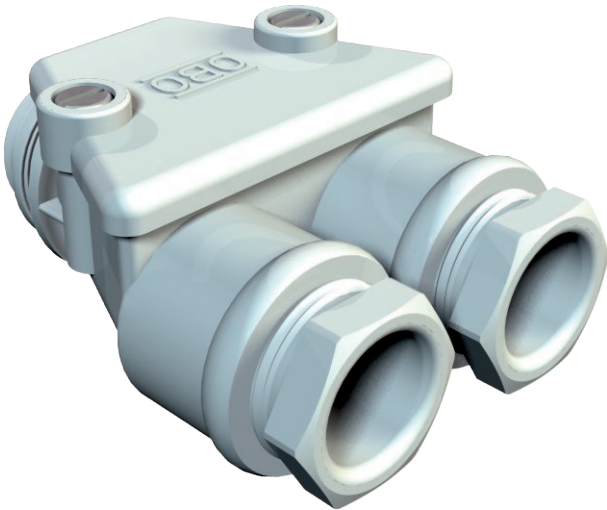

IP54 protection rating, with removable polystyrene lid, as well as two connection thread sealing rings made of polyethylene.
With connection thread M20 x 1.5,
2 half glands PG 13.5 for cable diameter 6.5–10.5 mm.



UF Duroplast, Aminoplast, type 131.5

Additional product text 1	113/M20: with connection thread M20 x 1.5, 2 half glands Pg 13.5 for cable diameter 6.5–10.5 mm.
---------------------------	--

Master data

Item no.	2024063
Type	113 M20 LGR
Description 1	Twin cable threaded connection
Dimension	M20
Colour	Light grey
RAL number	7035
Material	Duroplast, Aminoplast, type 131.5
Material symbol	UF
Smallest sales unit (VG)	5,00 Piece
Weight	3,70 kg/100 pc.


Technical data sheet

Twin gland, metric thread, light grey

Item no. 2024063



Technical data

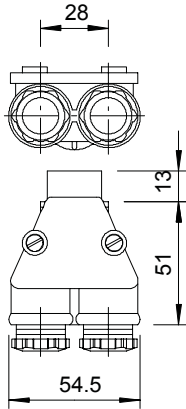

Version	Straight
Bend protection	☐
Sealing range D	6,50 - 10,50 mm
explosion-proof	☐
Flat cable threaded connection	☐
For Ex zone	Without
Flame resistant	Flame resistant to VDE 0471/DIN 695 Part 2-1, test temperature 650 °C
Thread	M 20 x 1,5
Thread type	Metric
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP54
Splittable gland	☐
Strain relief option	☐