

Technical data sheet

Cone cable gland, metric thread, light grey

Item no. 2035332



Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring with metric connection thread to IEC 423.
Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.
Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.

CE

IP 54

IP 65

M

PS

Polystyrene

Additional product text 1

Shock-resistant

Master data	
Item no.	2035332
Type	106 M 20 PS
Description 1	Cable gland
Dimension	M20
Colour	Light grey
RAL number	7035
Material	Polystyrene
Material symbol	PS
Smallest sales unit (VG)	50,00 Piece
Weight	0,75 kg/100 pc.


Technical data sheet

Cone cable gland, metric thread, light grey

Item no. 2035332



Technical data

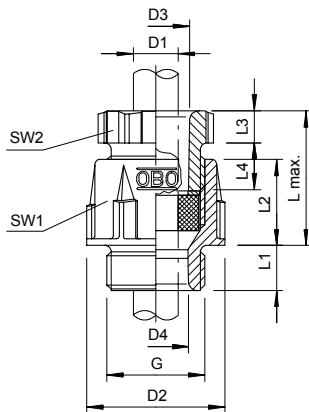

Dimension D2	27,00 mm
Dimension D3	13,40 mm
Dimension D4	13,50 mm
Dimension L max.	28,00 mm
Dimension L1	9,00 mm
Dimension L2	16,00 mm
Dimension L3	5,00 mm
Dimension L4	10,80 mm
SW 1	24,00 mm
SW 2	21,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	9,00 - 13,00 mm
explosion-proof	☐
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Thread	M20 x 1,5
Thread type	Metric
Thread length	9,00 mm
Nominal thread size	20,00
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☒
Protection rating	IP65
Splittable gland	☐
Strain relief option	☐