


# Technical data sheet

## Cone cable gland, metric thread, light grey

Item no. 2035359

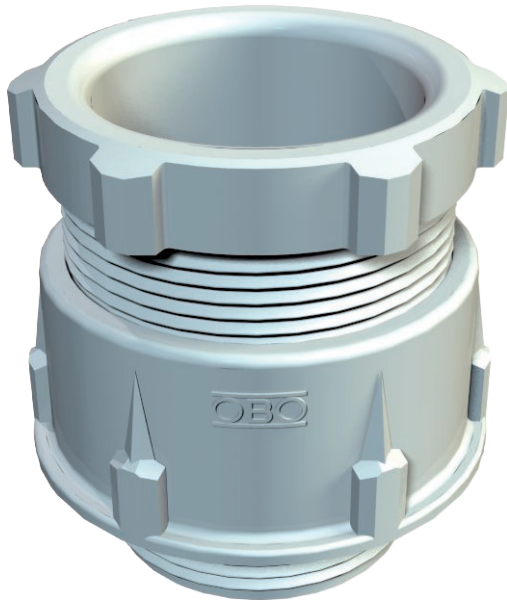

Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring with metric connection thread to IEC 423.  
Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.  
Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.



PS Polystyrene

Additional product text 1 Shock-resistant

### Master data

|                          |                 |
|--------------------------|-----------------|
| Item no.                 | 2035359         |
| Type                     | 106 M 32 PS     |
| Description 1            | Cable gland     |
| Dimension                | M32             |
| Colour                   | Light grey      |
| RAL number               | 7035            |
| Material                 | Polystyrene     |
| Material symbol          | PS              |
| Smallest sales unit (VG) | 10,00 Piece     |
| Weight                   | 2,89 kg/100 pc. |


# Technical data sheet

## Cone cable gland, metric thread, light grey

Item no. 2035359



### Technical data

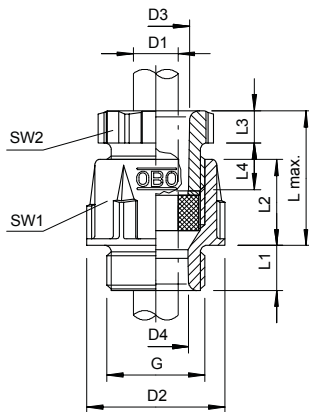

|                         |                                     |
|-------------------------|-------------------------------------|
| Dimension D2            | 47,50 mm                            |
| Dimension D3            | 30,30 mm                            |
| Dimension D4            | 26,00 mm                            |
| Dimension L max.        | 42,00 mm                            |
| Dimension L1            | 11,00 mm                            |
| Dimension L2            | 20,50 mm                            |
| Dimension L3            | 8,00 mm                             |
| Dimension L4            | 18,00 mm                            |
| SW 1                    | 42,00 mm                            |
| SW 2                    | 40,00 mm                            |
| Version                 | Straight                            |
| Type of seal            | Sealing ring                        |
| Bend protection         | <input type="checkbox"/>            |
| Sealing range D         | 18,00 - 25,00 mm                    |
| explosion-proof         | <input type="checkbox"/>            |
| For Ex zone             | Without                             |
| For Ex zone gas         | Without                             |
| For Ex zone dust        | Without                             |
| Thread                  | M32 x 1,5                           |
| Thread type             | Metric                              |
| Thread length           | 11,00 mm                            |
| Nominal thread size     | 32,00                               |
| Fibre-glass reinforced  | <input type="checkbox"/>            |
| Halogen-free            | <input checked="" type="checkbox"/> |
| Multiple sealing insert | <input type="checkbox"/>            |
| With locknut            | <input type="checkbox"/>            |
| Impact-resistant        | <input checked="" type="checkbox"/> |
| Protection rating       | IP65                                |
| Splittable gland        | <input type="checkbox"/>            |
| Strain relief option    | <input type="checkbox"/>            |