


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036134

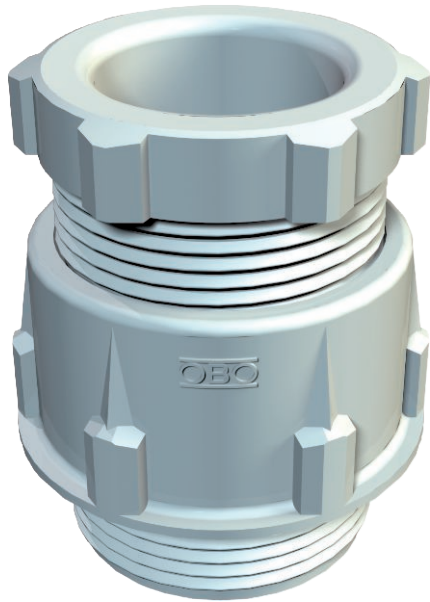

Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring.

PG connection thread in accordance with DIN 40430.

Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.



PS Polystyrene

Additional product text 1 Shock-resistant

Master data

Item no.	2036134
Type	106 PG13.5
Description 1	Cable gland
Dimension	PG13,5
Colour	Light grey
RAL number	7035
Material	Polystyrene
Material symbol	PS
Smallest sales unit (VG)	50,00 Piece
Weight	0,79 kg/100 pc.


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036134



Technical data

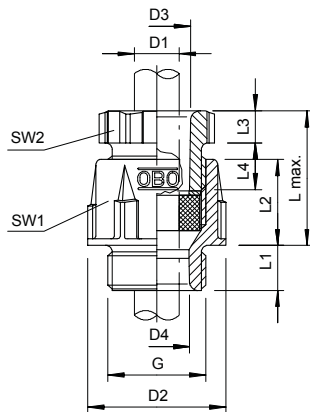

Dimension D2	27,00 mm
Dimension D3	13,40 mm
Dimension D4	13,50 mm
Dimension L max.	28,00 mm
Dimension L1	9,00 mm
Dimension L2	16,00 mm
Dimension L3	5,00 mm
Dimension L4	10,80 mm
SW 1	24,00 mm
SW 2	21,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	9,00 - 13,00 mm
explosion-proof	☐
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 13,5
Thread type	PG
Thread length	9,00 mm
Nominal thread size	13,50
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP65
Splittable gland	☐
Strain relief option	☐