


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036215

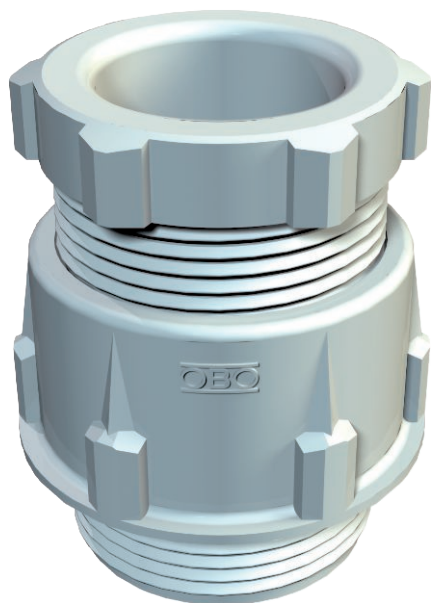

Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring.

PG connection thread in accordance with DIN 40430.

Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.




PS Polystyrene

Additional product text 1 Shock-resistant

Master data

Item no.	2036215
Type	106 PG21
Description 1	Cable gland
Dimension	PG21
Colour	Light grey
RAL number	7035
Material	Polystyrene
Material symbol	PS
Smallest sales unit (VG)	50 Piece
Weight	1,76 kg/100 pc.

Technical data

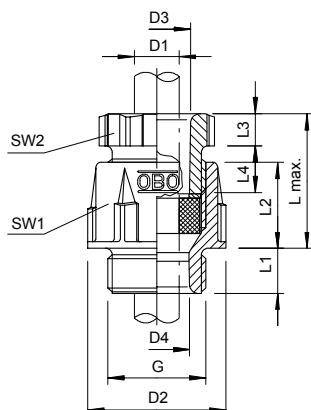

Dimension D2	37,50 mm
Dimension D3	21,20 mm
Dimension D4	21,00 mm
Dimension L max.	38,00 mm
Dimension L1	11,00 mm
Dimension L2	19,00 mm
Dimension L3	7,00 mm
Dimension L4	17,00 mm
SW 1	33,00 mm
SW 2	30,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	14,00 - 18,00 mm
explosion-proof	☐
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 21
Thread type	PG

Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036215



Technical data

Thread length	11,00 mm
Nominal thread size	21
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP65
Splittable gland	☐
Strain relief option	☐