

Technical data sheet

Cone cable gland, PG thread, strain relief, nickel-plated

Item no. 2046423



Cable gland with centrally acting transverse clip strain relief in the pressure screw, bend protection of movable cables through strongly rounded pressure screw.
With Pg connection thread to DIN 40430.
Pressure rings made of electrogalvanised and transparently passivated steel.
NR/SBR sealing ring.
Protection rating: with connection thread sealing ring IP 65, without connection thread sealing ring IP 54.
With hexagonal intermediate support (similar to shape C 4 to DIN 46320).
* Prices according to DEL notation.



CuZn	Brass
N	Nickel-plated

Master data

Item no.	2046423
Type	159 MS PG42
Description 1	Cable gland
Description 2	with outside hexagonal
Dimension	PG42
Material	Brass
Material symbol	CuZn
Surface	Nickel-plated
Surface symbol	N
Smallest sales unit (VG)	5,00 Piece
Weight	41,07 kg/100 pc.


Technical data sheet

Cone cable gland, PG thread, strain relief, nickel-plated

Item no. 2046423



Technical data

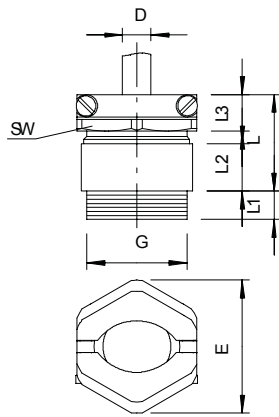

Dimension E	65,00 mm
Dimension L max.	43,00 mm
Dimension L1	10,00 mm
Dimension L2	22,00 mm
Dimension L3	16,30 mm
SW 1	57,00 mm
SW 2	59,00 mm
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	37,00 - 39,00 mm
explosion-proof	☐
Flat cable threaded connection	☐
For Ex zone	Without
Thread	Pg 42
Thread type	PG
Thread length	10,00 mm
Fibre-glass reinforced	☐
Halogen-free	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP65
Strain relief option	☒