


Technical data sheet

Wall and ceiling bracket

Item no. 6363750

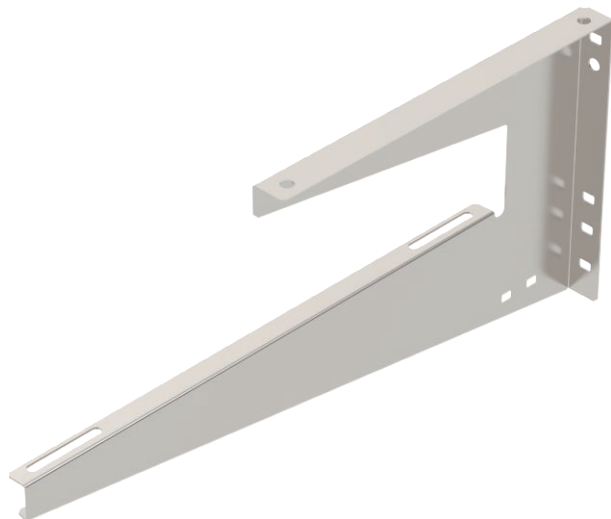

Wall and ceiling bracket for universal structural fastening.




VA	Stainless steel, rustproof 1.4301
2B	Bright, reworked

Master data

Item no.	6363750
Type	WDB L 400 A2
Description 1	Wall and ceiling bracket
Description 2	lightweight version
Dimension	B400mm
Material	Stainless steel, material no. 1.4301
Material symbol	A2
Surface	Bright, reworked
Surface symbol	2B
Smallest sales unit (VG)	1 Piece
Weight	73,00 kg/100 pc.

Technical data

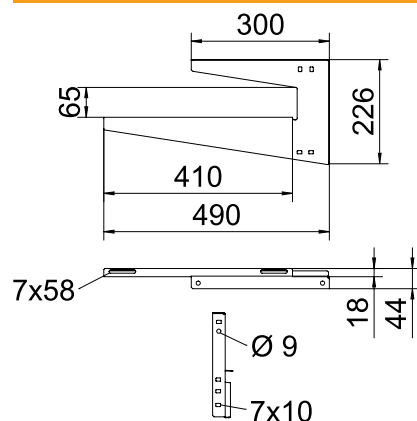

Length	490,00 mm
Width	410,00 mm
Height	226,00 mm
Dimension B	410,00 mm
Dimension H	226,00 mm
Dimension h1	65,00 mm
Dimension L	490,00 mm
Version	Suspension bracket (C clamp)
Tray fastening	Screw-on
F in ceiling	0,12 kN
F in kN wall	0,12 kN
for width	400,00 mm
for threaded rod	M8
For metric threaded rod	8
Suitable for tray/ladder width	400,00 mm
Suitable for maintaining electrical function	☐
Suitable for cable tray	☒
Suitable for cable ladder	☒
Suitable for mesh cable tray	☒
Hole diameter	7,00 mm
Material thickness	1,25 mm

Technical data sheet

Wall and ceiling bracket

Item no. 6363750



Technical data

Adjustable



Appr. load: