 


H

diffuser H slide
klosz H wsuwany
Abdeckung H einschiebbar
diffuseur H coulissant




material / materiał / Material / matériel:


PC

PP


PP

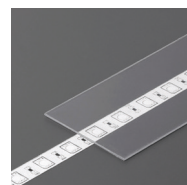

transparent
transparentny
transparent
transparent

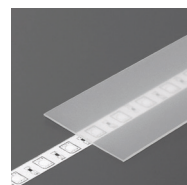

frosted
szron
satinert
givr 

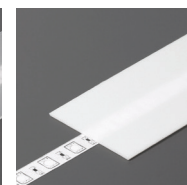

opal
mleczny
opal
opaque

1000 mm

23000116

2000 mm

23000216

3000 mm

-

23000139

23000239

23000339

23000138

 
23000238

-

FLAT8 H/UX → 114

I


diffuser I click
klosz I klik
Abdeckung I einclipsbar
diffuseur I clic




material / materiał / Material / matériel:

PC

PC

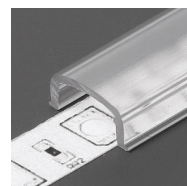

frosted
szron
satinert
givr 

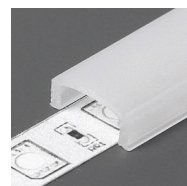

opal
mleczny
opal
opaque

1000 mm

86050000

2000 mm

86060000

3000 mm

86510000

4100 mm

86520000

86050038

86060038

86510038

86520038

PEN8 I → 172

J

diffuser J slide
klosz J wsuwany
Abdeckung J einschiebbar
diffuseur J coulissant




material / materiał / Material / matériel:

PC

PP


PP

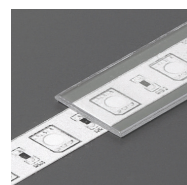

transparent
transparentny
transparent
transparent



frosted
szron
satinert
givr 

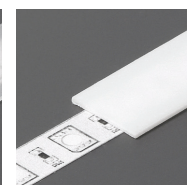

opal
mleczny
opal
opaque

1000 mm

70000116

2000 mm

70000216

3000 mm

-

70000139

70000239

70000339

70000138

70999238

-

 
BEGTON12 J/S → 36

BEGTIN12 J/S → 90

PEN12 CJ → 174

K

diffuser K click
klosz K klik
Abdeckung K einclipsbar
diffuseur K clic



material / materiał / Material / matériel:

PC



opal
mleczny
opal
opaque

1000 mm

B1030038

2000 mm

B1040038

3000 mm

B1050038

4100 mm

B1060038

FLOOR8 K → 158

FLOOR12 K/U → 160

UP-BOLD12 K → 184