


sling
zawiesie
Abhängung
suspension
→ 209



FIX16
→ 191

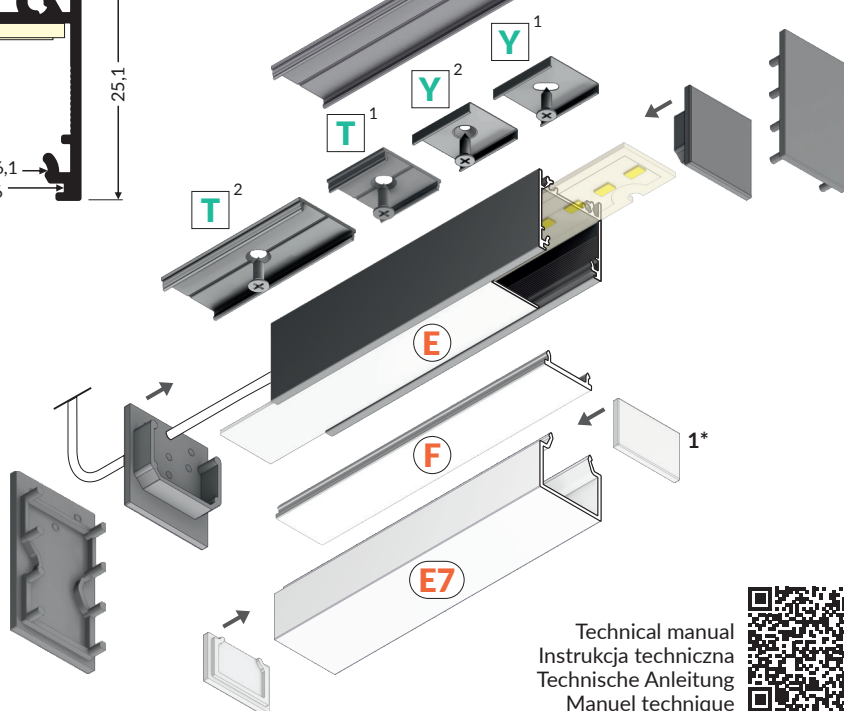

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique



Y¹ → 208

mounting plate Y
uchwyt Y
Halter Y
fixation Y

Y² → 208

mounting plate Y cone
uchwyt Y cone
Halter Y cone
fixation Y cône

T¹ → 204

mounting plate T
uchwyt T
Halter T
fixation T

T² → 204

connector T 180 deg
łącznik T 180 st
Verbinder T 180 Grad
connecteur T 180 degrés

E → 198

diffuser E slide
klosz E wsuwany
Abdeckung E einschiebbar
diffuseur E coulissant

F → 199


diffuser F click
klosz F klik
Abdeckung F einclipsbar
diffuseur F clic

E7 → 198


diffuser E7 click
klosz E7 klik
Abdeckung E7 einclipsbar
diffuseur E7 clic

1* → 198

end cap E7
zaślepka E7
Endkappe E7
embout E7

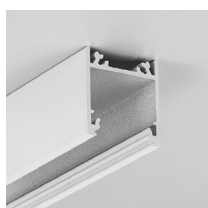

white painted
biały malowany
weiß lackiert
peint en blanc

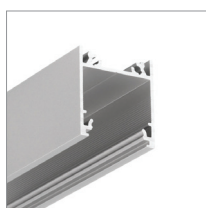

anodized
anodowany
eloxiert
surface anodisée




black anodized
czarny anodowany
schwarz eloxiert
noir anodisé



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut


1000 mm	C1010001	C1010020	C1010021	C1010000
2000 mm	C1020001	C1020020	C1020021	C1020000
3000 mm	C1050001	C1050020	C1050021	C1050000
4050 mm	C1060001	C1060020	C1060021	C1060000

end cap LINEA20
zaślepka LINEA20
Endkappe LINEA20
embout LINEA20

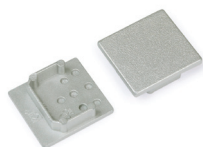

white biały weiß blanc	silver srebrny silbern argent
C1940001	C1940040
black czarny schwarz noir	grey szary grau gris
C1940002	C1940022

end cap LINEA20-E7
zaślepka LINEA20-E7
Endkappe LINEA20-E7
embout LINEA20-E7

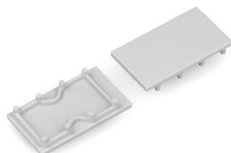

white biały weiß blanc	silver srebrny silbern argent
C1999901	C1999940
black czarny schwarz noir	grey szary grau gris
C1999902	C1999922

LED mounting LINEA20
mocowanie LED LINEA20
LED Montageteil LINEA20
fixation LED LINEA20



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	C6050000
2000 mm	C6060000
3000 mm	C6070000
4050 mm	C6080000

material: aluminium
materiał: aluminium
Material: Aluminium
matériel: aluminium

