



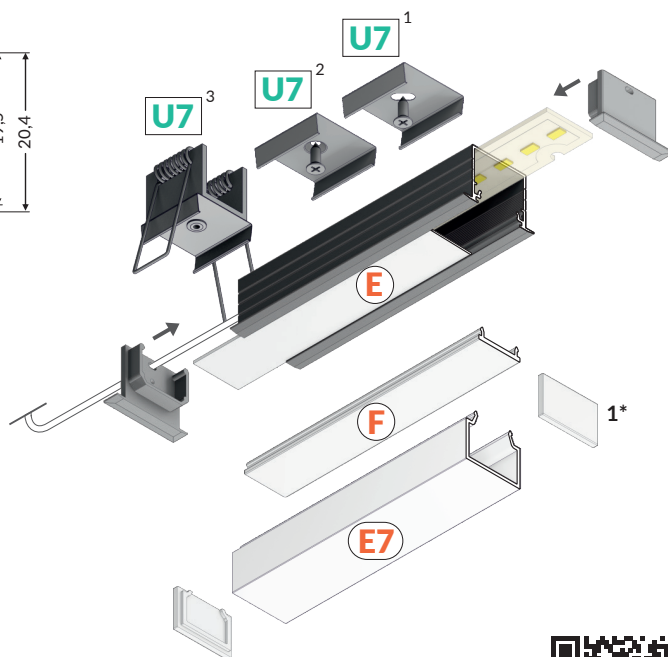

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

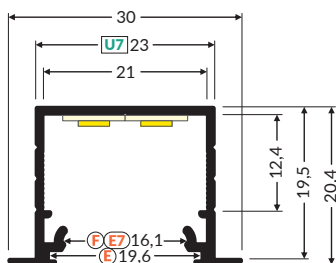

U7¹ → 206

mounting plate U7
uchwyt U7
Halter U7
fixation U7

U7² → 206

mounting plate U7 cone
uchwyt U7 cone
Halter U7 cone
fixation U7 cône

U7³ → 206

mounting plate U7 spring
uchwyt U7 sprężyna
Halter U7 Feder
fixation U7 ressort

E → 198

diffuser E slide
klosz E wsuwany
Abdeckung E einschiebbar
diffuseur E coulissant

F → 199

diffuser F click
klosz F klik
Abdeckung F einclipsbar
diffuseur F clic

E7 → 198


diffuser E7 click
klosz E7 klik
Abdeckung E7 einclipsbar
diffuseur E7 clic

1* → 198


end cap E7
zaślepka E7
Endkappe E7
embout E7




white painted
biały malowany
weiß lackiert
peint en blanc

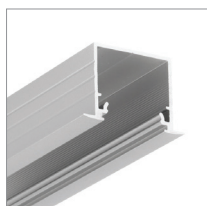

anodized
anodowany
eloxiert
surface anodisée

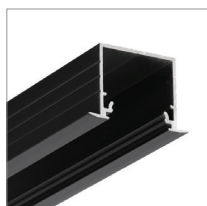


black anodized
czarny anodowany
schwarz eloxiert
noir anodisé

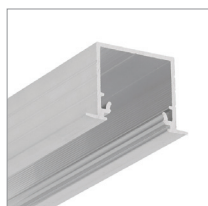

raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	E4010001	E4010020	E4010021	E4010000
2000 mm	E4020001	E4020020	E4020021	E4020000
3000 mm	E4030001	E4030020	E4030021	E4030000
4050 mm	E4040001	E4040020	E4040021	E4040000

end cap LINEA-IN20 with hole
zaślepka LINEA-IN20 z otworem
Endkappe LINEA-IN20 mit Öffnung
embout LINEA-IN20 avec un trou

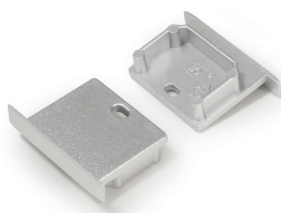

white biały weiß blanc	silver srebrny silbern argent
E4990001	E4990040
black czarny schwarz noir	grey szary grau gris
E4990002	E4990022

end cap LINEA-IN20-E7 with hole
zaślepka LINEA-IN20-E7 z otworem
Endkappe LINEA-IN20-E7 mit Öffnung
embout LINEA-IN20-E7 avec un trou



white biały weiß blanc	silver srebrny silbern argent
E4999901	E4999940
black czarny schwarz noir	grey szary grau gris
E4999902	E4999922