


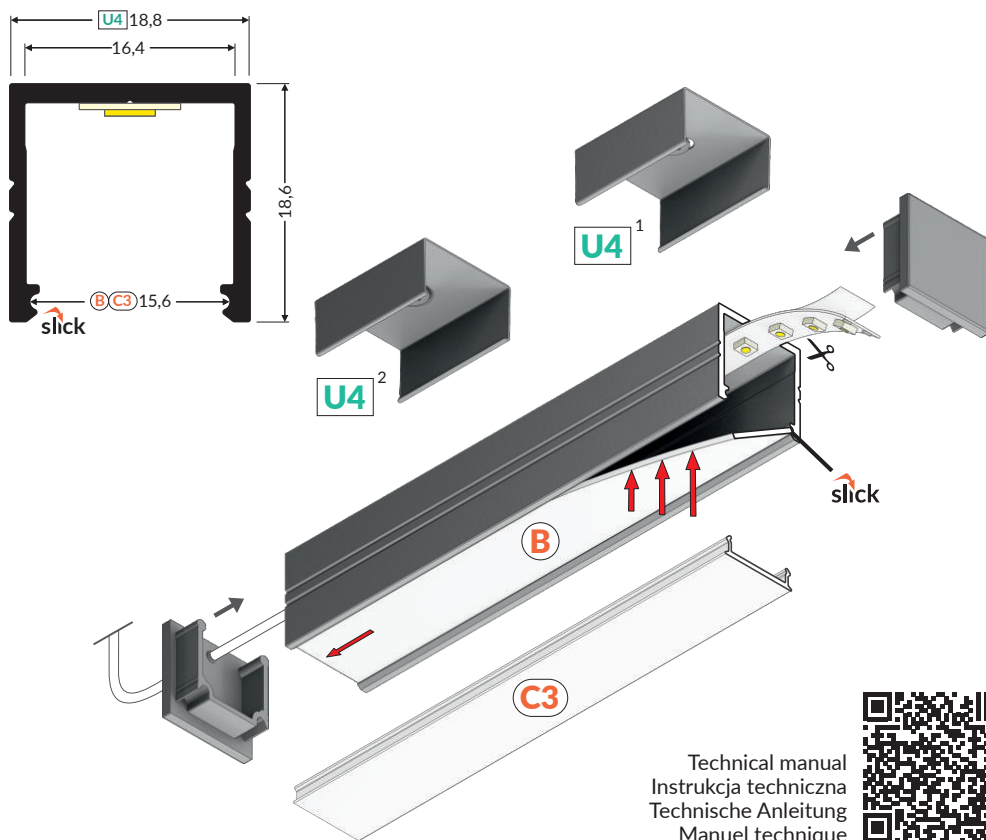

U4¹ → 205

mounting plate U4
uchwyt U4
Halter U4
fixation U4

U4² → 205

mounting plate U4 cone
uchwyt U4 cone
Halter U4 cone
fixation U4 cône

B → 194

diffuser B slide
klosz B wsuwany
Abdeckung B einschiebbar
diffuseur B coulissant


C3 → 196

diffuser C3 click
klosz C3 klik
Abdeckung C3 einclipsbar
diffuseur C3 clic

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique



white painted
biały malowany
weiß lackiert
peint en blanc

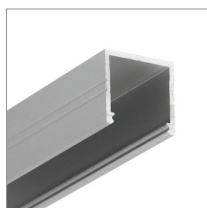

anodized
anodowany
eloxiert
surface anodisée




black anodized
czarny anodowany
schwarz eloxiert
noir anodisé



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	F1010001	F1010020	F1010021	F1010000
2000 mm	F1020001	F1020020	F1020021	F1020000
3000 mm	F1030001	F1030020	F1030021	F1030000
4050 mm	F1040001	F1040020	F1040021	F1040000

end cap SMART16-BC3
zaślepka SMART16-BC3
Endkappe SMART16-BC3
embout SMART16-BC3

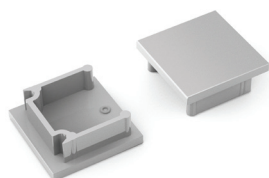

white
biały
weiß
blanc
F1999901

silver
srebrny
silbern
argent
F1999940

black
czarny
schwarz
noir
F1999902

grey
szary
grau
gris
F1999922