


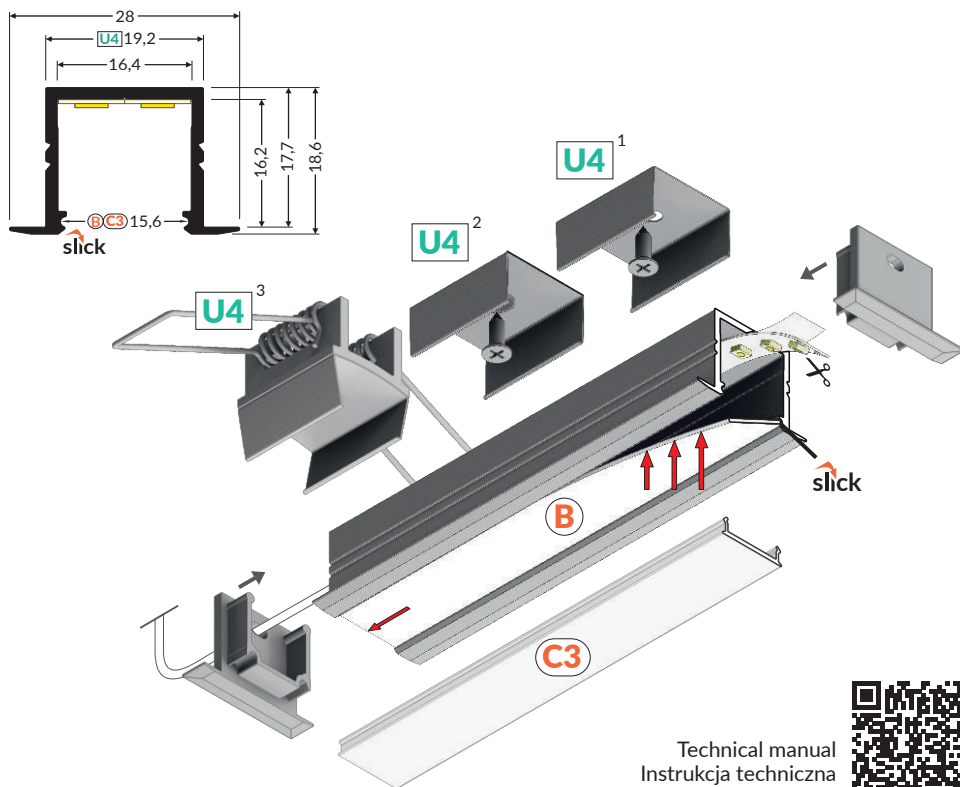

U4¹ → 205

mounting plate U4
uchwyt U4
Halter U4
fixation U4

U4² → 205

mounting plate U4 cone
uchwyt U4 cone
Halter U4 cone
fixation U4 cône

U4³ → 205

mounting plate U4 spring
uchwyt U4 sprężyna
Halter U4 Feder
fixation U4 ressort


B → 194

diffuser B slide
klosz B wsuwany
Abdeckung B einschiebbar
diffuseur B coulissant


C3 → 196

diffuser C3 click
klosz C3 klik
Abdeckung C3 einclipsbar
diffuseur C3 clic

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

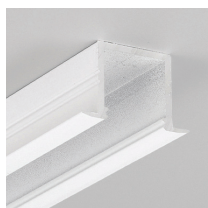

white painted
biały malowany
weiß lackiert
peint en blanc

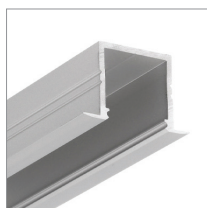

anodized
anodowany
eloxiert
surface anodisée




raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	F6000101
2000 mm	F6000201
3000 mm	F6000301
4050 mm	F6000401

F6000120
F6000220
F6000320
F6000420

F6000100
F6000200
F6000300
F6000400

end cap SMART-IN16-BC3 with hole
zasłlepka SMART-IN16-BC3 z otworem
Endkappe SMART-IN16-BC3 mit Öffnung
embout SMART-IN16-BC3 avec un trou

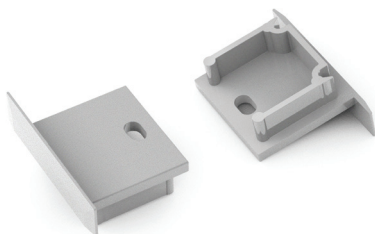

white biały weiß blanc	silver srebrny silbern argent
F6999901	F6999940

grey szary grau gris
F6999922

