
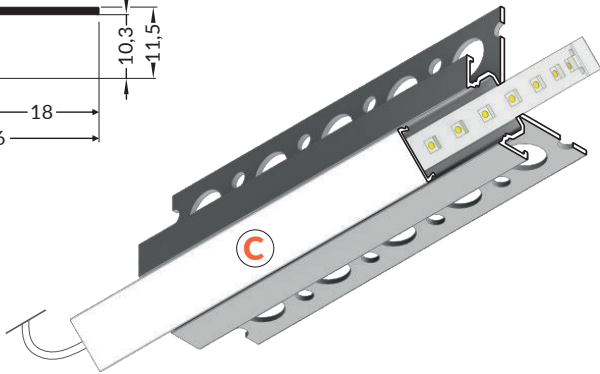


UNI-TILE12 270 deg / st / grad / degrés **C** plus

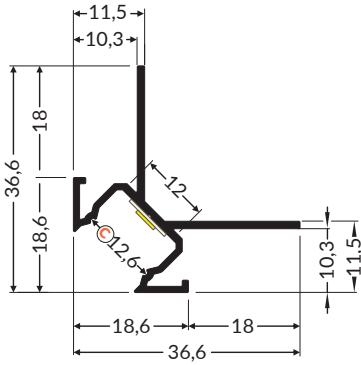

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

C → 195


diffuser C click
klosz C klik
Abdeckung C einclipsbar
diffuseur C clic



more
information



więcej
szczegółów

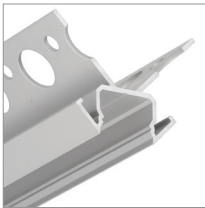

anodized
anodowany
eloxiert
surface anodisée

1000 mm	G3000520
2000 mm	G3000620
3000 mm	G3000820
4050 mm	G3000920

