




Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique



LED profile SKIRT10
profil LED SKIRT10
LED Profil SKIRT10
profilé LED SKIRT10

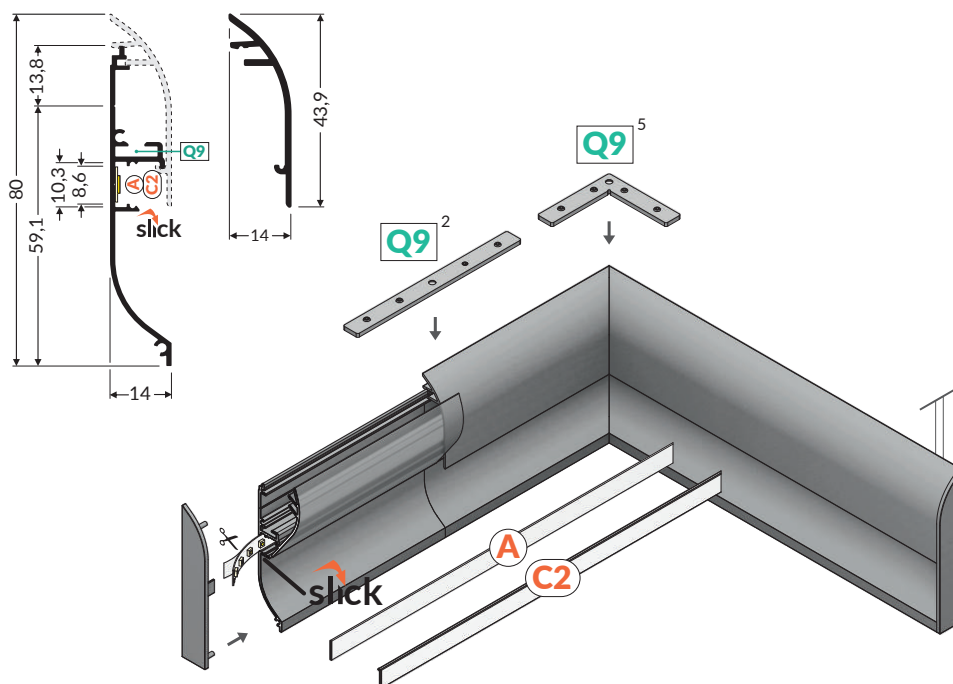

white painted
biały malowany
weiß lackiert
peint en blanc



anodized
anodowany
eloxiert
surface anodisée



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	J2000101	J2000120	J2000100
2000 mm	J2000201	J2000220	J2000200
3000 mm	J2000301	J2000320	J2000300
4050 mm	J2000401	J2000420	J2000400

complementary profile SKIRT10
profil uzupełniający SKIRT10
Ergänzungsprofil SKIRT10
cache SKIRT10



white painted
biały malowany
weiß lackiert
peint en blanc



anodized
anodowany
eloxiert
surface anodisée



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	J2000501	J2000520	J2000500
2000 mm	J2000601	J2000620	J2000600
3000 mm	J2000701	J2000720	J2000700
4050 mm	J2000801	J2000820	J2000800

Q9¹ → 203

connector Q9 90 deg bent
łącznik Q9 90 st gięty
Verbinder Q9 90 Grad gebogen
connecteur Q9 90 degrés pliable

Q9² → 203

connector Q9 180 deg
łącznik Q9 180 st
Verbinder Q9 180 Grad
connecteur Q9 180 degrés

Q9³ → 203

connector Q9 135 deg
łącznik Q9 135 st
Verbinder Q9 135 Grad
connecteur Q9 135 degrés

Q9⁴ → 203

connector Q9 120 deg
łącznik Q9 120 st
Verbinder Q9 120 Grad
connecteur Q9 120 degrés

Q9⁵ → 203

connector Q9 90 deg
łącznik Q9 90 st
Verbinder Q9 90 Grad
connecteur Q9 90 degrés

Q9⁶ → 203

connector Q9 60 deg
łącznik Q9 60 st
Verbinder Q9 60 Grad
connecteur Q9 60 degrés

Q9⁷ → 203

connector Q9 45 deg
łącznik Q9 45 st
Verbinder Q9 45 Grad
connecteur Q9 45 degrés


A → 194

diffuser A slide
klosz A wsuwany
Abdeckung A einschiebbar
diffuseur A coulissant

C2 → 196

diffuser C2 click
klosz C2 klik
Abdeckung C2 einclipsbar
diffuseur C2 clic

end cap SKIRT10
zaślepka SKIRT10
Endkappe SKIRT10
embout SKIRT10

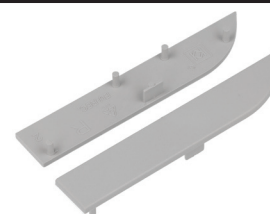

white
biały
weiß
blanc

silver
srebrny
silbern
argent

grey
szary
grau
gris

J2998901

J2998940

J2998922