




Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

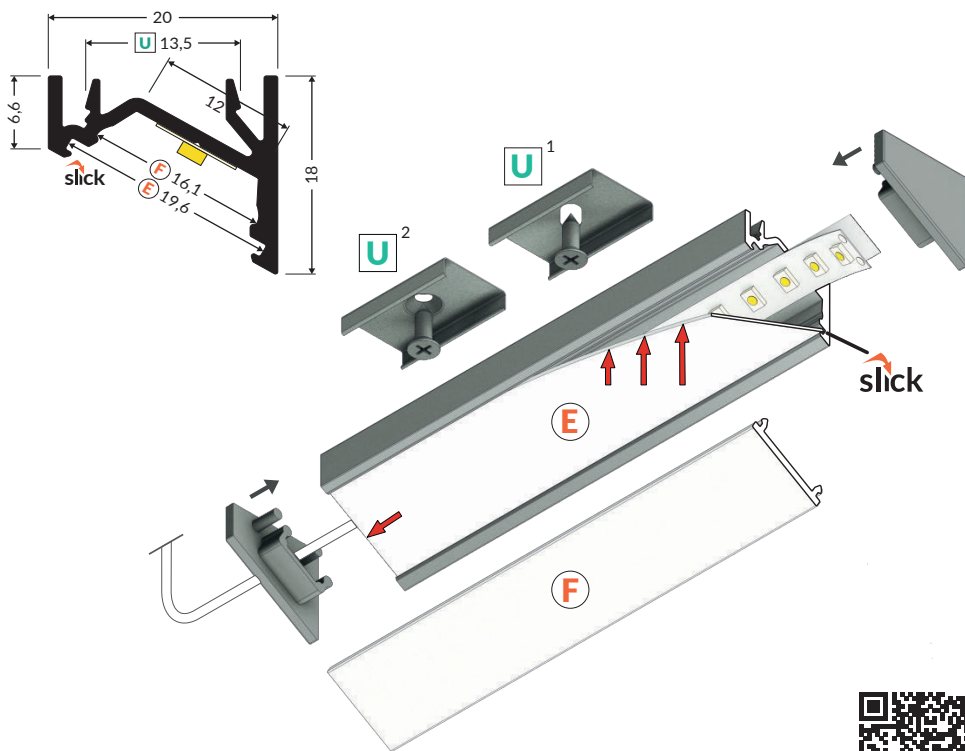

U¹ → 204

mounting plate U
uchwyt U
Halter U
fixation U

U² → 204

mounting plate U cone
uchwyt U cone
Halter U cone
fixation U cône

E → 198

diffuser E slide
klosz E wsuwany
Abdeckung E einschiebbar
diffuseur E coulissant

F → 199

diffuser F click
klosz F klik
Abdeckung F einclipsbar
diffuseur F clic



white painted
biały malowany
weiß lackiert
peint en blanc



anodized
anodowany
eloxiert
surface anodisée




black anodized
czarny anodowany
schwarz eloxiert
noir anodisé



raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	J7000101	J7000120	J7000121	J7000100
2000 mm	J7000201	J7000220	J7000221	J7000200
3000 mm	J7000301	J7000320	J7000321	J7000300
4050 mm	J7000401	J7000420	J7000421	J7000400

end cap CORNER12.v2
zaślepka CORNER12.v2
Endkappe CORNER12.v2
embout CORNER12.v2

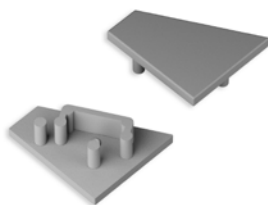

white
biały
weiß
blanc
J7999901

silver
srebrny
silbern
argent
J7999940

black
czarny
schwarz
noir
J7999902

grey
szary
grau
gris
J7999922

