



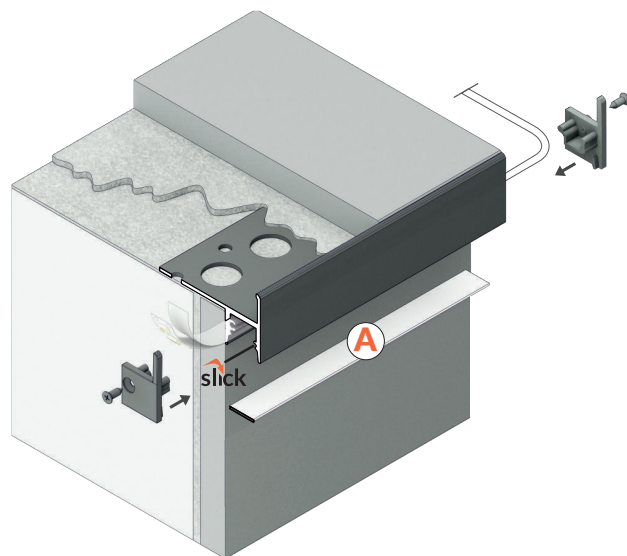

**A** → 194


diffuser A slide  
klosz A wsuwany  
Abdeckung A einschiebbar  
diffuseur A coulissant

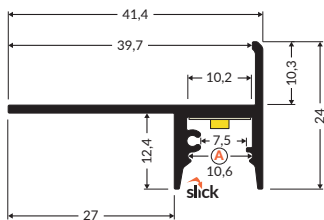

anodized  
anodowany  
eloxiert  
surface anodisée

|         |                 |
|---------|-----------------|
| 1000 mm | <b>J8000120</b> |
| 2000 mm | <b>J8000220</b> |
| 3000 mm | <b>J8000320</b> |
| 4050 mm | <b>J8000420</b> |

end cap UP-TILE10  
zaślepka UP-TILE10  
Endkappe UP-TILE10  
embout UP-TILE10

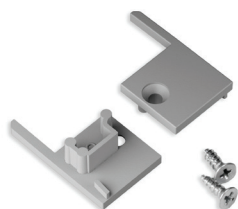

silver  
srebrny  
silbern  
argent  
**J8999940**

grey  
szary  
grau  
gris  
**J8999922**

