
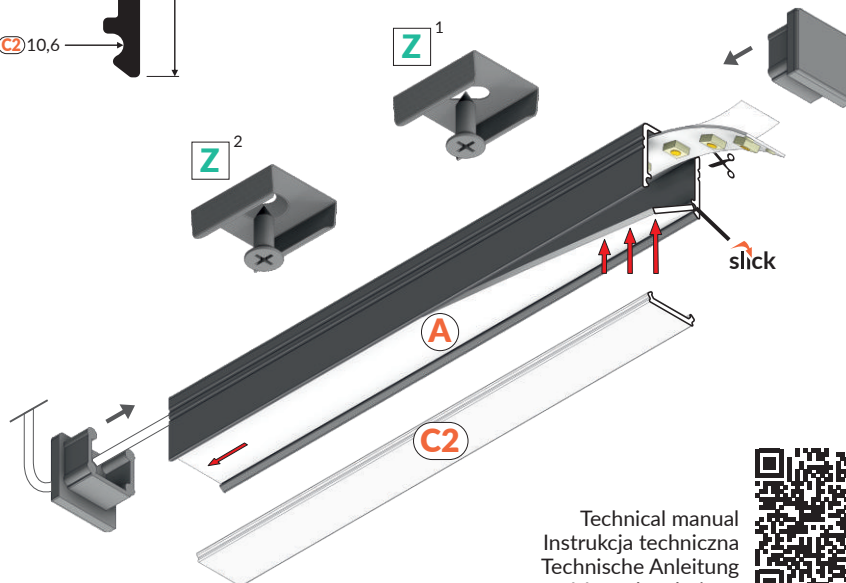


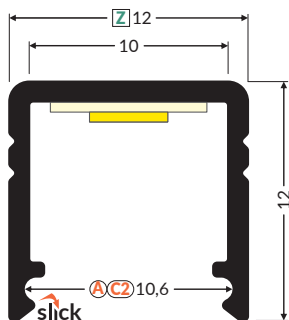

Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

Z¹ → 208

mounting plate Z
uchwyt Z
Halter Z
fixation Z

Z² → 208

mounting plate Z cone
uchwyt Z cone
Halter Z cone
fixation Z cône

A → 194


diffuser A slide
klosz A wsuwany
Abdeckung A einschiebbar
diffuseur A coulissant

C2 → 196


diffuser C2 click
klosz C2 klik
Abdeckung C2 einclipsbar
diffuseur C2 clic




white painted
biały malowany
weiß lackiert
peint en blanc

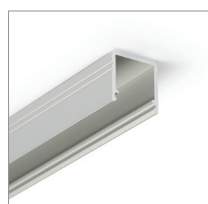

anodized
anodowany
eloxiert
surface anodisée

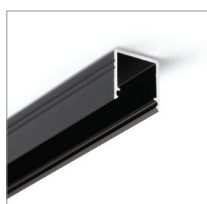


black anodized
czarny anodowany
schwarz eloxiert
noir anodisé

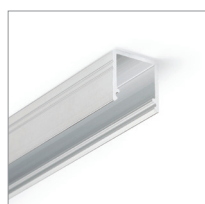

raw aluminium
surowe aluminium
Rohaluminium
aluminium brut


1000 mm	C2010001	C2010020	C2010021	C2010000
2000 mm	C2020001	C2020020	C2020021	C2020000
3000 mm	C2030001	C2030020	C2030021	C2030000
4050 mm	C2040001	C2040020	C2040021	C2040000

end cap SMART10
zaślepka SMART10
Endkappe SMART10
embout SMART10

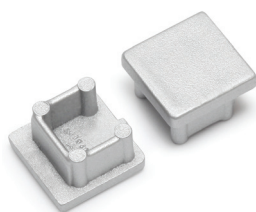

white biały weiß blanc	silver srebrny silbern argent
C2940001	C2940040
black czarny schwarz noir	grey szary grau gris
C2940002	C2940022

end cap SMART10 with hole
zaślepka SMART10 z otworem
Endkappe SMART10 mit Öffnung
embout SMART10 avec un trou

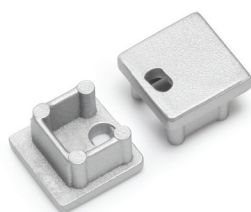

white biały weiß blanc	silver srebrny silbern argent
C2960001	C2960040
black czarny schwarz noir	grey szary grau gris
C2960002	C2960022

connector SMART10 90 deg
łącznik SMART10 90 st
Verbinder SMART10 90 Grad
connecteur SMART10 90 degrés

material: aluminium
materiał: aluminium
Material: Aluminium
matériel: aluminium

white painted
biały malowany
weiß lackiert
peint en blanc
C2910001

anodized
anodowany
eloxiert
surface anodisée
C2910020

black anodized
czarny anodowany
schwarz eloxiert
noir anodisé
C2910021

