





Technical manual
Instrukcja techniczna
Technische Anleitung
Manuel technique

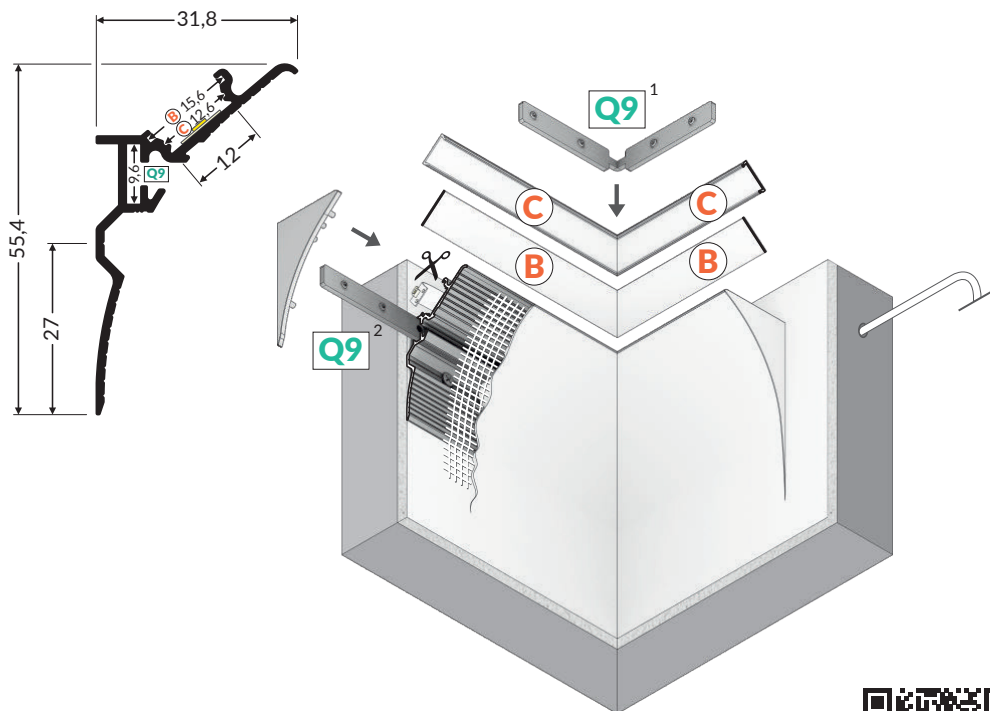

raw aluminium
surowe aluminium
Rohaluminium
aluminium brut

1000 mm	H9000100
2000 mm	H9000200
3000 mm	H9000300
4050 mm	H9000400

end cap SMOOTH12
zaślepka SMOOTH12
Endkappe SMOOTH12
embout SMOOTH12

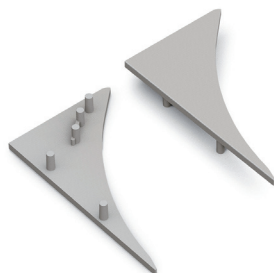

grey
szary
grau
gris
H9999922

Q9¹ → 203

connector Q9 90 deg bent
łącznik Q9 90 st gięty
Verbinder Q9 90 Grad gebogen
connecteur Q9 90 degrés plié

Q9² → 203

connector Q9 180 deg
łącznik Q9 180 st
Verbinder Q9 180 Grad
connecteur Q9 180 degrés

Q9³ → 203

connector Q9 135 deg
łącznik Q9 135 st
Verbinder Q9 135 Grad
connecteur Q9 135 degrés

Q9⁴ → 203

connector Q9 120 deg
łącznik Q9 120 st
Verbinder Q9 120 Grad
connecteur Q9 120 degrés

Q9⁵ → 203

connector Q9 90 deg
łącznik Q9 90 st
Verbinder Q9 90 Grad
connecteur Q9 90 degrés

Q9⁶ → 203

connector Q9 60 deg
łącznik Q9 60 st
Verbinder Q9 60 Grad
connecteur Q9 60 degrés

Q9⁷ → 203

connector Q9 45 deg
łącznik Q9 45 st
Verbinder Q9 45 Grad
connecteur Q9 45 degrés

B → 194

diffuser B slide
klosz B wsuwany
Abdeckung B einschiebbar
diffuseur B coulissant

C → 195

diffuser C click
klosz C klik
Abdeckung C einclipsbar
diffuseur C clic

