

Long nose pliers with side cutter

506/1BI



Profiles




Standards

DIN ISO 5745

Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head polished
- surface finish: chrome plated to standard ISO 1456:2009
- heavy duty double - component handles
- gripping surface serrated
- made according to standard ISO 5745
- also for clenching and separating of from cables and other sensitive objects

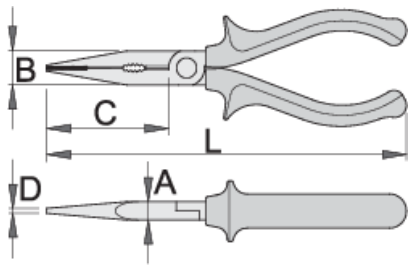

	L	B	D	A	C	
607874	140	15	2	8	39	115
607875	160	16	2.5	9	49	137

cutting capacity (10N=1kg)

	L	max 1600 N/mm ² Ø↑	max 650 N/mm ² Ø↑
607874	140	1,6	2,0
607875	160	1,6	2,0

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Photo (pictures)



Frequently asked questions

The head profile on the screw has deformed to such an extent that it cannot be unscrewed with a screwdriver. Which Unior tool can be used in this case?
 407/4DP screw pliers are the best choice for unscrewing screws with a damaged head profile.