

Long nose pliers with side cutter and pipe grip, bent

512/1BI




Profiles



Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head polished
- surface finish: chrome plated according to ISO 1456:2009
- heavy duty double - component handles
- gripping surface serrated
- jaws bent to an angle of 45°
- the long bent jaws enable simple and precise clenching of nuts and screws
- the strong jaws enable good grip
- made according to standard ISO 5745

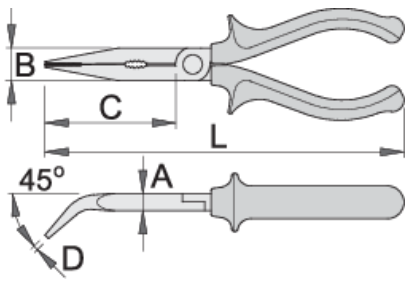


	L	B	D	A	C	
607966	170	17	2.5	9	61	152
607967	200	17	2.5	9	77	204

cutting capacity (10N=1kg)

	L	max 1600 N/mm ² Ø↑	max 650 N/mm ² Ø↑
607966	170	1,6	2,0
607967	200	1,8	2,5

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Usage (pictures)

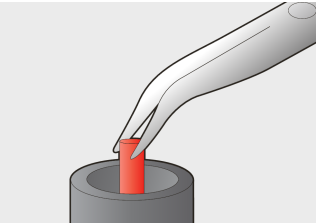

Frequently asked questions

The head profile on the screw has deformed to such an extent that it cannot be unscrewed with a screwdriver. Which Unior tool can be used in this case?
 407/4DP screw pliers are the best choice for unscrewing screws with a damaged head profile.