

Double groove joint pliers

445/4G



Profiles



Standards


DIN ISO 8976

Product features

- material: premium chrome vanadium steel
- drop forged, entirely hardened and tempered
- head surface finish: finely ground
- surface finish: phosphated to standard ISO 9717
- heavy duty plastic handles
- made according to standard ISO 8976

Advantages:

- jaw aperture adjustable in 5 positions for dim. 180, for dim. 240 and 300 in 6 positions
- grooved joint

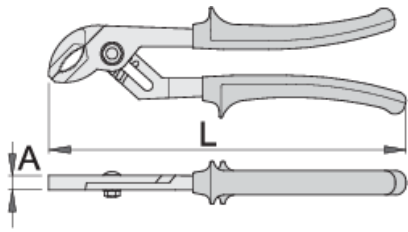

	L	A	O _{max}	
608690	180	9.9	25	197
620558	240	10.8	35	417
608692	300	12.2	40	657

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Usage (pictures)

