

Long nose pliers with side cutter and pipe grip, straight

508/4G



Profiles




Standards

DIN ISO 5745

Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head surface finish: finely ground
- surface finish: phosphated to standard ISO 9717
- heavy duty plastic handles
- gripping surface serrated
- made according to standard ISO 5745
- also for clenching and separating of from cables and other sensitive objects

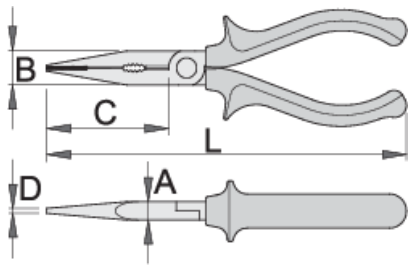

	L	B	D	A	C	
608710	170	17	2.5	9	61	156
608711	200	17	2.5	9	77	191

cutting capacity (10N=1kg)

	L	max 1600 N/mm² Ø↑	max 650 N/mm² Ø↑
608710	170	1,6	2,0
608711	200	1,8	2,5

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Frequently asked questions

The head profile on the screw has deformed to such an extent that it cannot be unscrewed with a screwdriver. Which Unior tool can be used in this case?
 407/4DP screw pliers are the best choice for unscrewing screws with a damaged head profile.