

Long nose pliers with side cutter and pipe grip, bent

512/4G




Profiles



Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head surface finish: finely ground
- surface finish: phosphated to standard ISO 9717
- gripping surface serrated
- jaws bent to an angle of 45°
- heavy duty plastic handles
- the long bent jaws enable simple and precise clenching of nuts and screws
- the strong jaws enable good grip

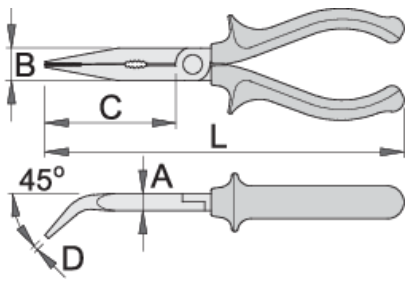


	L	B	D	A	C	
608720	170	17	2.5	9	61	152
608721	200	17	2.5	9	77	204

cutting capacity (10N=1kg)

	L	max 1600 N/mm ² Ø↑	max 650 N/mm ² Ø↑
608720	170	1,6	2,0
608721	200	1,8	2,5

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Usage (pictures)

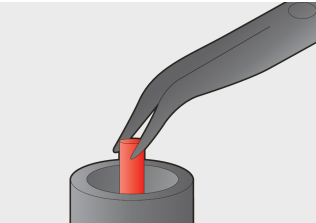

Frequently asked questions

The head profile on the screw has deformed to such an extent that it cannot be unscrewed with a screwdriver. Which Unior tool can be used in this case?
 407/4DP screw pliers are the best choice for unscrewing screws with a damaged head profile.