

Insulated single open end wrench

110/2VDEDP



Profiles



Standards

DIN EN IEC 60900 (VDE 0682-201):2019-04; EN IEC 60900:2018

Product features


- material: premium chrome vanadium steel
- head: chrome plated according to ISO 1456:2009
- made according to standard ISO 7738 and EN IEC 60900:2018

Advantages:

- double layered - double coloured insulation for additional safety
- controlled according to standard EN IEC 60900

Important!

- if second layer is visible, replace your insulated tool with a new one.

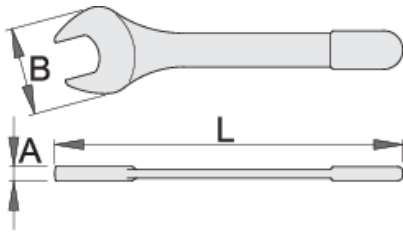

		L	B	A	
618370	6	72	16	6.9	19
618331	7	82	16.1	6.9	26
617801	8	95	21	7	30
621575	9	100	24.5	7.5	35
612175	10	105	24.5	7.5	42
612176	11	112	26	7.5	51
612177	12	125	28	8	65
612178	13	132	30.5	8.5	76
612179	14	140	33	8.5	84
612180	15	150	35	9	96
621576	16	154	40	10	118
612181	17	157	40	10	137
621577	18	165	44	11	151
612182	19	170	44	11	170
618333	20	175	46.4	12.2	184
619201	21	180	48.8	12.5	213
612183	22	195	49	13	234
618335	23	210	52.8	13.1	251
612184	24	220	56	14	311
621578	26	235	59	15	361
617802	27	240	59	15	387
621579	28	245	66	15.8	440
618336	30	260	66.1	15.8	518
618337	32	275	71.4	17.6	620

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Usage (pictures)

