

Waterpump pliers

447/4PHPP



Profiles




Product features

- material: premium chrome vanadium steel
- drop forged, entirely hardened and tempered
- surface finish: phosphated to standard ISO 9717
- head surface finish: finely ground
- handles plastic dipped

Advantages:

- toothed jaw is designed to ensure optimum grip of an object
- jaw aperture adjustable in 10 positions
- The HPP pliers have a button for fast regulation of the jaw's gap which enables fast and precise adaptation of the jaw to the size of the work piece.
- Extreme grip strength: The design and shape of the pliers' jaws enable, despite the slim construction, better grip strength of the work piece, which results in stability, safety, and greater effectiveness.
- Finish: pliers are drop forged from high quality tool steels and heat treated
- Work: due to the slim construction, the jaws enable one-handed work in difficult-to-reach places
- Ergonomics: handles are designed to fully adjust to the user's hand and so enable greater handling and work safety

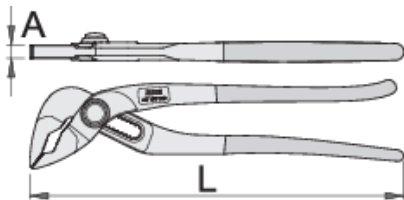

L

A

O_{max}



620421

240

8.5

40

353

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.