

Multifunctional diagonal cutting nippers

462/4G



Profiles




Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head surface finish: finely ground
- surface finish: phosphated to standard ISO 9717
- heavy duty plastic handles

Advantages:

- Stripping off insulation of single conductors 1,5 mm² and 2,5mm²

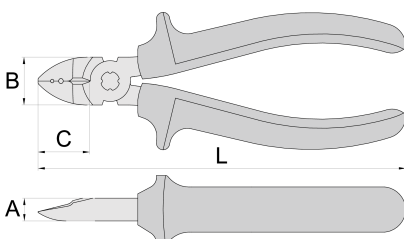

	L	B	A	C	
624062	160	21	10	22	205

cutting capacity (10N=1kg)

	L	max 1600 N/mm² Ø↑	max 650 N/mm² Ø↑
624062	160	1,6	2,5

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.