

# Spring-loaded test probe

## GKS-075 214 064 A 2802 M

Item GKS-075-0405



**ingun**<sup>®</sup>

Partner for Future Technology

### General data

|                                |                                  |
|--------------------------------|----------------------------------|
| Product group                  | Screw-in test probe              |
| Sub-product group              | Screw-in test probe              |
| Series                         | GKS-075 M screw-in               |
| Grid                           | 1.91 mm [75 mil]                 |
| Contacting from                | Pad, Pin, Post                   |
| Magnetic                       | Yes                              |
| Installation type              | Screw-in                         |
| Quick-exchange system          | Yes                              |
| Adjustable installation height | No                               |
| Non-rotating                   | No                               |
| Screw-in torque                | 0.5 - 1 cNm [.044 - .088 lbf-in] |
| Compatible receptacle(s)       | KS-075 M                         |
| Min. temperature               | - 40 °C [- 104 °F]               |
| Max. temperature               | + 80 °C [+ 176 °F]               |
| RoHS-compliant                 | RoHS-3;6a;6c                     |

### Electrical data


|                                       |          |
|---------------------------------------|----------|
| Current load capacity / rated current | 3 A      |
| Typical resistance (Ri)               | <20 mOhm |

### Mechanical data

|                                |                   |
|--------------------------------|-------------------|
| Total length                   | 35.9 mm [1.41 in] |
| Barrel diameter                | 1 mm [.039 in]    |
| Maximum stroke                 | 6.35 mm [.25 in]  |
| Spring pre-load                | 1.03 N [3.70 ozf] |
| Collar height                  | .02               |
| Spring force at working stroke | 2.8 N [10.0 ozf]  |
| Recommended working stroke     | 4.3 mm [.169 in]  |

### Tip style data


|                    |                                 |
|--------------------|---------------------------------|
| Tip style          | 14 4-point crown, self-cleaning |
| Tip diameter       | 0.64 mm [.025 in]               |
| Tip style surface  | A gold                          |
| Tip style material | 2 steel                         |

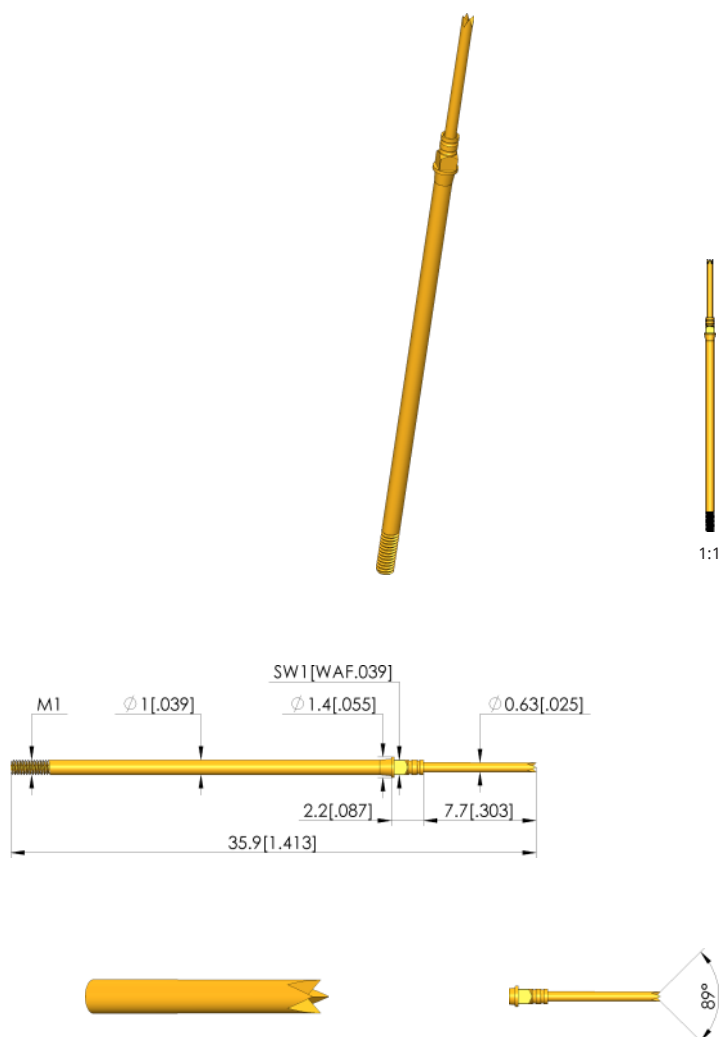

Spring-loaded test probe  
**GKS-075 214 064 A 2802 M**  
Item GKS-075-0405



**ingun**<sup>®</sup>  
Partner for Future Technology

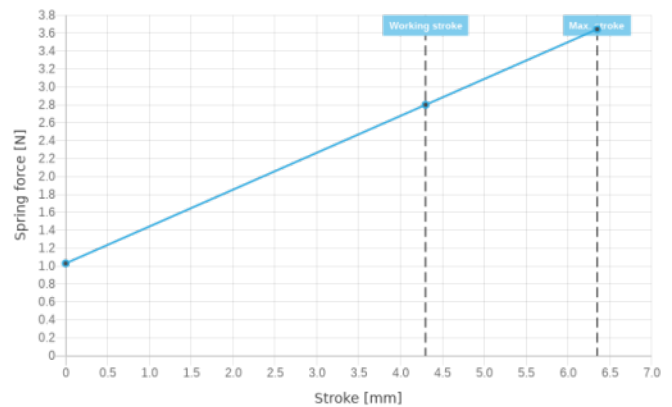

**INGUN Prüfmittelbau GmbH**

Max-Stromeyer-Straße 162  
78467, Constance, Germany  
Phone +49 7531 8105-0  
Customer hotline +49 7531 8105-888  
Fax +49 7531 8105-65  
info@ingun.com



Prices and delivery times on request.  
Technical changes reserved. 07/23 EN

Learn more about  
Screw-in test probe



SCREW-IN TEST PROBE

ingun.com