

NO MERCURY ADDED


Description	: Mercury Free Alkaline Manganese Battery, AAA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø10.5 mm x 44.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Warranty Period	: 36 months
Average Weight	: 12.5g

Cross References:



GP	JIS	IEC	Eveready	Duracell	Varta
24AU	LR03	LR03	E92	MX2400	4003

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
20 Ohms	24 Hrs/Day	0.9V	19.2Hrs

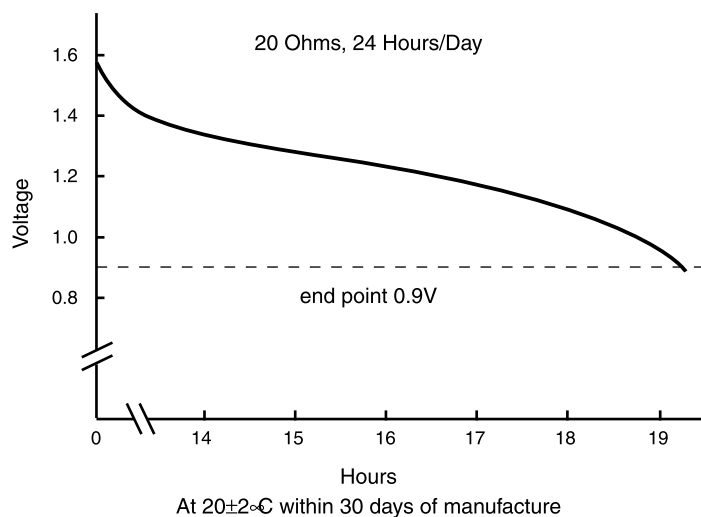

Model No.: **GP24AUP**

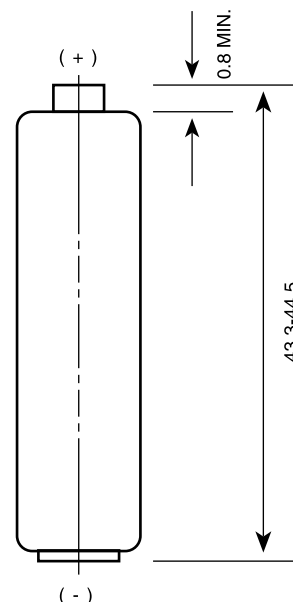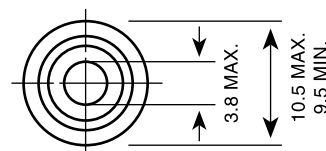

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.